


Kabel koneksi dengan soket

ADOAH032ZDB0005E03

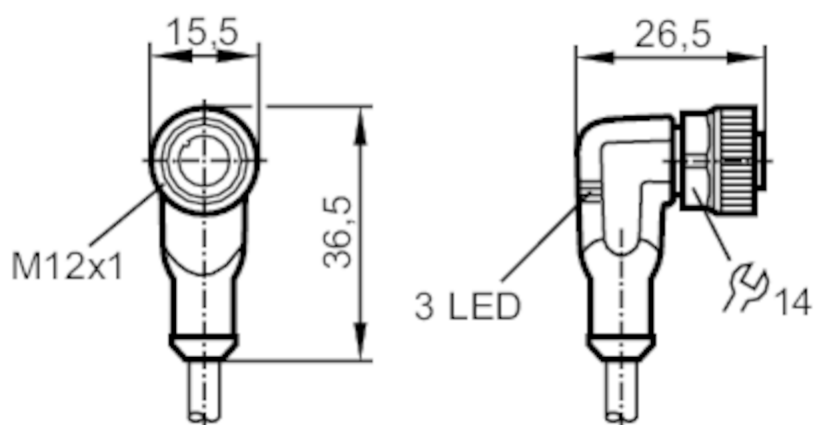

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	10...36 DC
Kelas perlindungan	II
Total beban arus maks. [A]	4

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-25...70
Suhu sekitar (bergerak) [°C]	5...70
Perlindungan	IP 65; IP 67

Data teknis

Berat [g]	173.3
Dimensi [mm]	26.5 x 15.5 x 36.5
Material	casing: TPU hitam transparan; Segel: FKM
Material mur	kuningan, berlapis nikel
Kesesuaian rantai tarik	ya



Kabel koneksi dengan soket

ADOAH032ZDB0005E03

Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan	1 Mio.
	ketegangan torsional	± 180 °/m

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik


Kabel: 5 m, PVC, hitam, Ø 4.5 mm; 3 x 0.25 mm² (14 x Ø 0.15 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

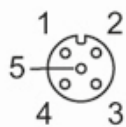

Koneksi

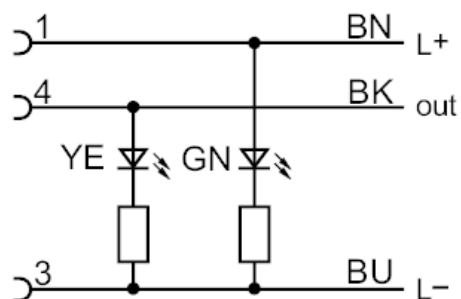

Warna core :
 BK = hitam
 BN = coklat
 BU = biru