


Set lengan muting

4P-RETRO-REFLECTIVE-SENSORS

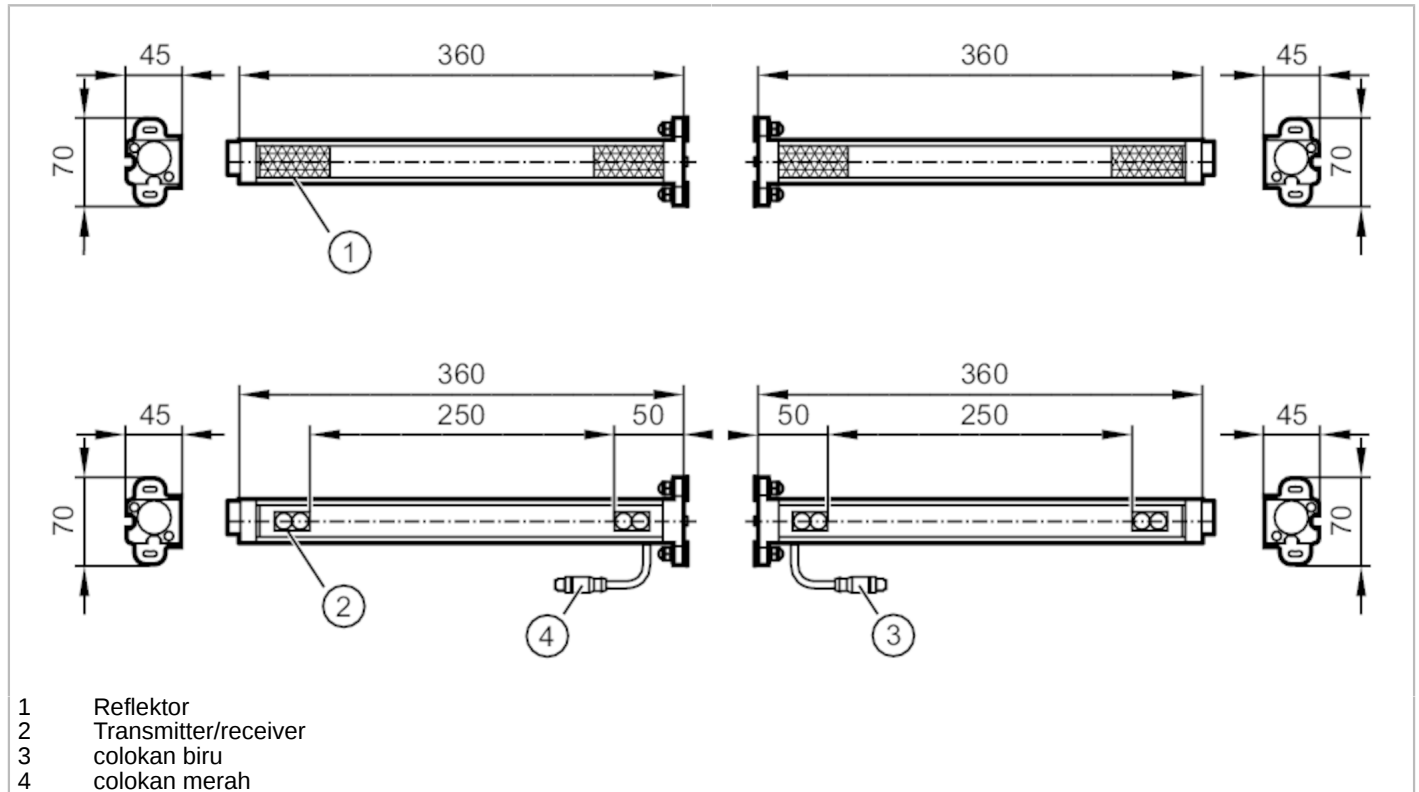

Karakteristik produk

Tipe cahaya	cahaya inframerah
-------------	-------------------

Aplikasi

Desain	muting sekuensial dengan empat sensor retro-reflektif paralel
Prinsip fungsi	Sensor retro-reflektif

Data kelistrikan

Tegangan pengoperasian [V]	19.2...28.8 DC
Konsumsi arus [mA]	60
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Tipe cahaya	cahaya inframerah
Panjang gelombang [nm]	940

Output

Desain kelistrikan	PNP
Fungsi output	mode dark-on
Penurunan tegangan maks. pada output peralihan DC [V]	0.5
Peringkat arus permanen dari output peralihan DC [mA]	100
Pelindung hubung singkat	ya
Pelindung beban berlebih	ya




Set lengan muting

4P-RETRO-REFLECTIVE-SENSORS


Zona pendeteksian		
Jarak jangkauan	[m]	< 2.5
Kondisi pengoperasian		
Suhu sekitar	[°C]	-30...55
Perlindungan		IP 65
Pengujian/persetujuan		
EME	EN 60947-5-2	
Data teknis		
Berat	[g]	3530
Material		aluminium; polipropilena
Material lensa		polikarbonat-ABS
Keterangan		
Jumlah paket		4 buah

Koneksi listrik - transmitter 1

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: biru

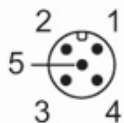

Koneksi

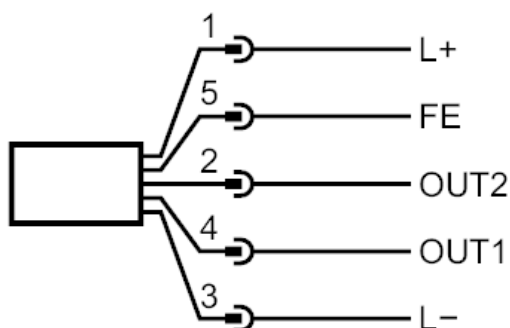

4 OUT 1 output peralihan
2 OUT 2 output peralihan

Set lengan muting


4P-RETRO-REFLECTIVE-SENSORS

Koneksi listrik - transmitter 2

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: merah



Koneksi

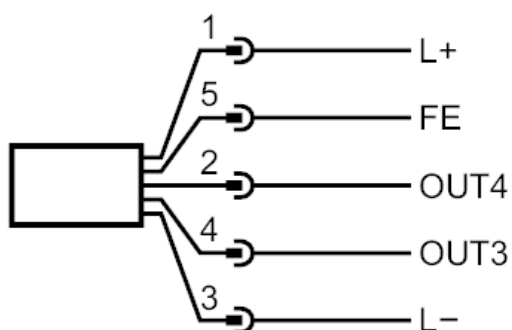

4 OUT 3	output peralihan
2 OUT 4	output peralihan