


EY5054



Kabel koneksi Y

Y SPLITTER CABLE LOW RANGE

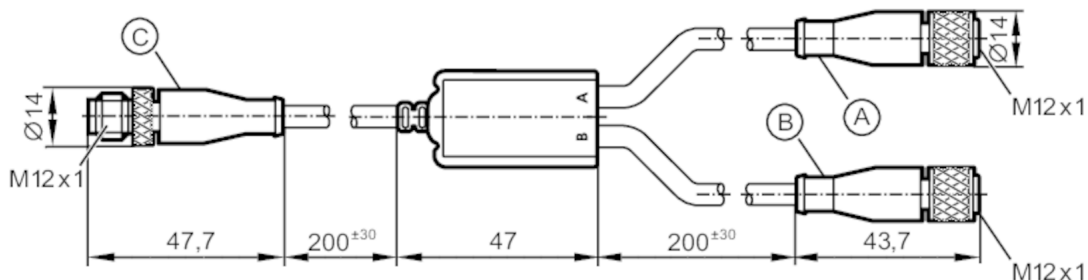

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	24 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	3

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Data teknis

Berat	[g]	58.7
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Material penyegel		FKM
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 15 x diameter kabel
	siklus pembengkokan	> 1 Mio.

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan C

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.5...0.8 Nm






Kabel koneksi Y

Y SPLITTER CABLE LOW RANGE

Koneksi listrik - Kabel


Kabel: 0.45 m, PVC, Bebas halogen, hitam, Ø 4.2 mm; 3 x 0.25 mm²

Koneksi

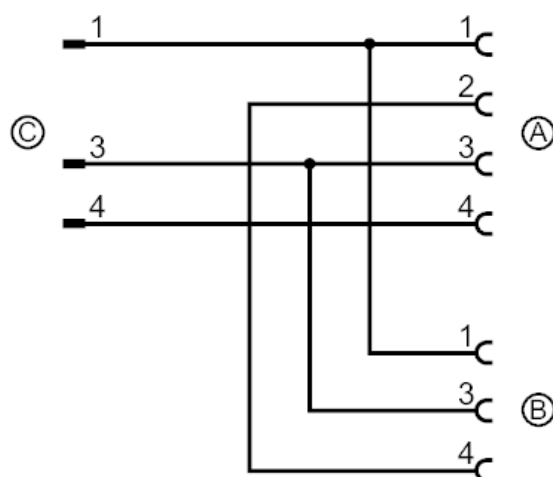

Koneksi listrik - soket A

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Segel: FKM; Kontak: dilapisi emas; Torsi pengencangan: 0.5...0.8 Nm

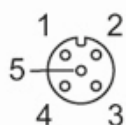

Koneksi listrik - soket B

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Segel: FKM; Kontak: dilapisi emas; Torsi pengencangan: 0.5...0.8 Nm

