


Sensor induktif

IB-4020-CPKG/20m

Produk tidak tersedia - entri arsip

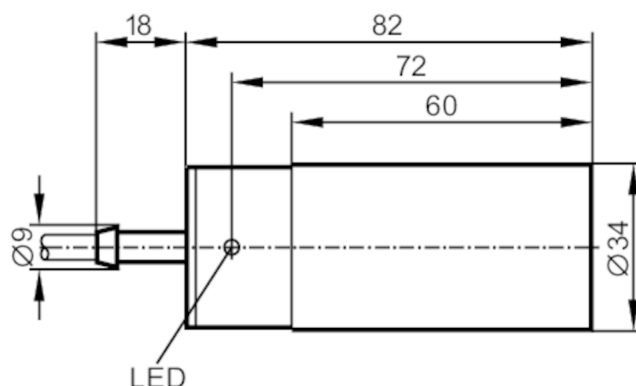

Karakteristik produk

Desain kelistrikan	PNP
Fungsi output	komplementer
Jangkauan pendeteksian [mm]	20
Casing	berbentuk silinder
Dimensi [mm]	Ø 34 / L = 82

Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC
Pelindung polaritas terbalik	ya

Output

Desain kelistrikan	PNP
Fungsi output	komplementer
Peringkat arus permanen dari output peralihan DC [mA]	200
Frekuensi peralihan DC [Hz]	40
Pelindung hubung singkat	ya
Tipe pelindung hubung singkat	berpulsa
Pelindung beban berlebih	ya

Zona pendeteksian

Jangkauan pendeteksian [mm]	20
Jangkauan pendeteksian real Sr [mm]	20 ± 10 %
Jarak pengoperasian [mm]	0...16.2

Akurasi/deviasi

Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / kuningan: 0.54 / aluminium: 0.5 / tembaga: 0.46
Histeresis [X01]	1...15
Deviasi titik peralihan [X01]	-10...10

Kondisi pengoperasian

Suhu sekitar [°C]	-25...80
Perlindungan	IP 67


IB5105



Sensor induktif

IB-4020-CPKG/20m

Pengujian/persetujuan		
EME	EN 60947-5-2	
Data teknis		
Casing	berbentuk silinder	
Pemasangan	non-flush mountable	
Dimensi	[mm]	Ø 34 / L = 82
Material	PBT	
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim	Klem pemasangan: 1	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
Kabel: 20 m, PVC; 4 x 0.5 mm ²		
Koneksi		

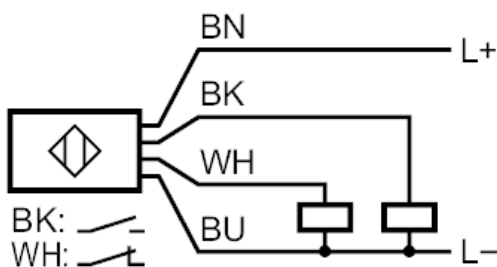

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih