


## Sensor induktif

IFA2004-ABOW/SL/10m

Produk tidak tersedia - entri arsip

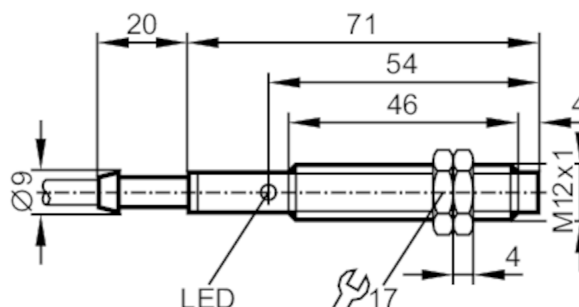

## Karakteristik produk

|                             |  |                  |
|-----------------------------|--|------------------|
| Fungsi output               |  | biasanya terbuka |
| Jangkauan pendeteksian [mm] |  | 4                |
| Casing                      |  | tipe berulir     |
| Dimensi [mm]                |  | M12 x 1 / L = 71 |

## Data kelistrikan

|                              |  |             |
|------------------------------|--|-------------|
| Frekuensi AC [Hz]            |  | 47...63     |
| Tegangan pengoperasian [V]   |  | 90...250 AC |
| Kelas perlindungan           |  | II          |
| Pelindung polaritas terbalik |  | tidak       |

## Output

|                                                         |  |                               |
|---------------------------------------------------------|--|-------------------------------|
| Fungsi output                                           |  | biasanya terbuka              |
| Penurunan tegangan maks. pada output peralihan AC [V]   |  | 8.5                           |
| Arus beban minimal [mA]                                 |  | 8                             |
| Kebocoran arus maks. [mA]                               |  | 3 (250 V AC) / 1.5 (120 V AC) |
| Peringkat arus permanen dari output peralihan AC [mA]   |  | 200; (250 (...50 °C))         |
| Peringkat arus jangka pendek dari output peralihan [mA] |  | 900; (20 ms / 0,5 Hz)         |
| Frekuensi peralihan AC [Hz]                             |  | 25                            |
| Pelindung hubung singkat                                |  | tidak                         |
| Pelindung beban berlebih                                |  | tidak                         |

## Zona pendeteksian

|                                |  |          |
|--------------------------------|--|----------|
| Jangkauan pendeteksian [mm]    |  | 4        |
| Jangkauan pendeteksian real Sr |  | 4 ± 10 % |
| Jarak pengoperasian [mm]       |  | 0...3.25 |

## Akurasi/deviasi

|                               |  |                                                                                 |
|-------------------------------|--|---------------------------------------------------------------------------------|
| Faktor koreksi                |  | baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2 |
| Histeresis [X01]              |  | 1...15                                                                          |
| Deviasi titik peralihan [X01] |  | -10...10                                                                        |


# IF0168



## Sensor induktif

IFA2004-ABOW/SL/10m

| Kondisi pengoperasian                     |                  |                              |
|-------------------------------------------|------------------|------------------------------|
| Suhu sekitar                              | [°C]             | -25...80                     |
| Perlindungan                              |                  | IP 67                        |
| Data teknis                               |                  |                              |
| Casing                                    |                  | tipe berulir                 |
| Pemasangan                                |                  | non-flush mountable          |
| Dimensi                                   | [mm]             | M12 x 1 / L = 71             |
| Penamaan ulir                             |                  | M12 x 1                      |
| Material                                  |                  | kuningan berlapis nikel; PBT |
| Elemen display/pengoperasian              |                  |                              |
| Display                                   | status peralihan | 1 x LED, kuning              |
| Aksesori                                  |                  |                              |
| Item dikirim                              |                  | mur pengunci: 2              |
| Keterangan                                |                  |                              |
| Jumlah paket                              |                  | 1 buah                       |
| Koneksi listrik                           |                  |                              |
| Kabel: 10 m, PVC; 3 x 0.5 mm <sup>2</sup> |                  |                              |
| Koneksi                                   |                  |                              |

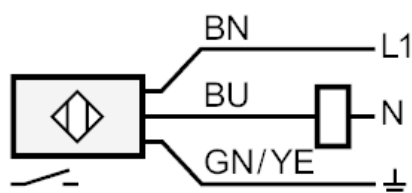

BN =           Warna core :  
BU =           coklat  
GN/YE =       biru  
                  hijau/kuning