


IFA2004-FRKG/V4A/US-100-IRF X

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!



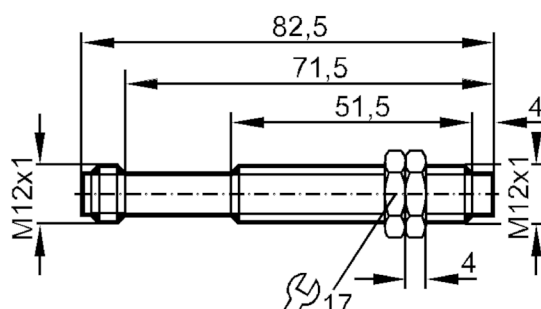

Sensor induktif

IFA2004-FRKG/V4A/US-100-IRF X

Tipe pelindung hubung singkat	berpulsa
Pelindung beban berlebih	ya

Zona pendeteksian

Jangkauan pendeteksian [mm]	4
Jangkauan pendeteksian real Sr	$4 \pm 10 \%$
Jarak pengoperasian [mm]	0...3.25

Akurasi/deviasi

Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / kuningan: 0.5 / aluminium: 0.4 / tembaga: 0.3
Histeresis [X01]	3...15
Deviasi titik peralihan [X01]	-10...10

Kondisi pengoperasian

Suhu sekitar [°C]	-25...80
Perlindungan	IP 67

Pengujian/persetujuan

EME	EN 60947-5-2
-----	--------------

Data teknis

Casing	tipe berulir
Pemasangan	non-flush mountable
Dimensi [mm]	M12 x 1
Penamaan ulir	M12 x 1
Material	baja tahan karat (1.4571 / 316Ti); PBT

Aksesori



Item dikirim	mur pengunci: 2
--------------	-----------------

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Koneksi

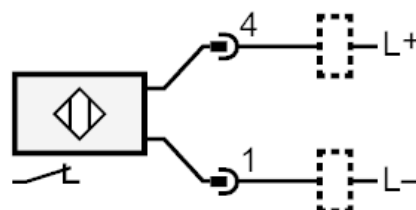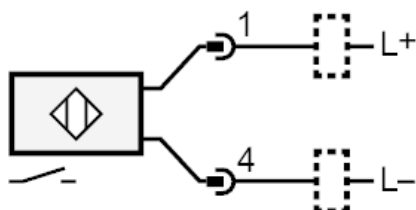

Konektor: 1 x M12