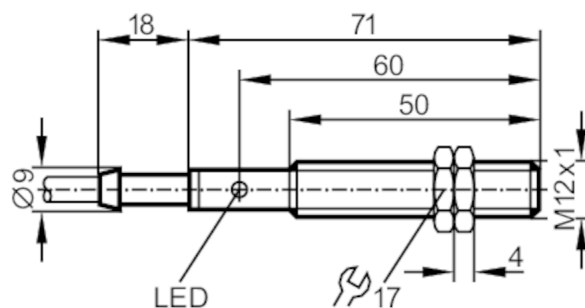


IFA3002-APKG/10m

Produk tidak tersedia - entri arsip


$$M12 \times 1 / L = 71$$

va

0...1.6

1...15

IF5303



Sensor induktif

IFA3002-APKG/10m

Deviasi titik peralihan	[X01]	-10...10
-------------------------	-------	----------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	1874

Data teknis

Casing		tipe berulir
Pemasangan		flush mountable
Dimensi	[mm]	M12 x 1 / L = 71
Penamaan ulir		M12 x 1
Material		kuningan dilapisi perunggu putih; permukaan pendeteksian: PC

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Aksesori

Item dikirim		mur pengunci: 2
--------------	--	-----------------


Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 10 m, PVC; 3 x 0.34 mm²

Koneksi

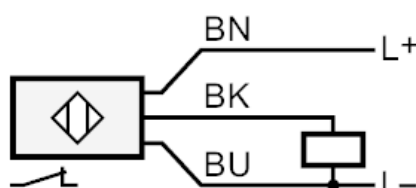

BN =	Warna core :
BU =	coklat
BK =	biru
	hitam