

IGA2008-ABOA/V4A



Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2
----------------	---



Sensor induktif

IGA2008-ABOA/IV4A

Histeresis	[X01]	1...15
Deviasi titik peralihan	[X01]	-10...10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	604

Data teknis

Berat	[g]	151.2
Casing		tipe berulir
Pemasangan		non-flush mountable
Dimensi	[mm]	M18 x 1 / L = 80
Penamaan ulir		M18 x 1
Material		baja tahan karat (1.4571 / 316Ti); PBT tidak berwarna

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Koneksi listrik

Perlindungan yang diperlukan	sekring miniatur sesuai IEC60127-2 lembar 1; ≤ 2 A; cepat
------------------------------	--

Aksesori

Item dikirim	mur pengunci: 2
--------------	-----------------

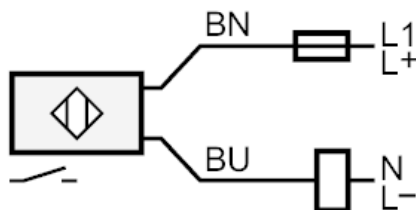
Keterangan

Keterangan	Rekomendasi: Periksa keamanan fungsi unit setelah hubung singkat.
Jumlah paket	1 buah

Koneksi listrik

Kabel: 2 m, PVC; 2 x 0.5 mm²

Koneksi

Catatan sekring miniatur sesuai IEC60127-2 lembar 1 ≤ 2 A cepat