


IGA3008-BPKG/6M




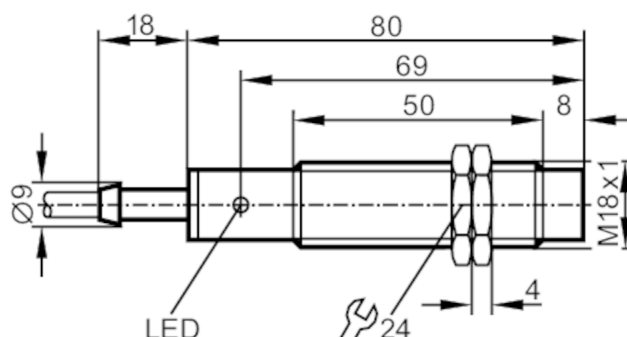

Sensor induktif

IGA3008-BPKG/6M

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Pengujian/persetujuan		
EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	1853
Data teknis		
Berat	[g]	361
Casing		tipe berulir
Pemasangan		non-flush mountable
Dimensi	[mm]	M18 x 1 / L = 80
Penamaan ulir		M18 x 1
Material		kuningan dilapisi perunggu putih; permukaan pendeteksian: PC
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim		mur pengunci: 2
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 6 m, PVC; 3 x 0.5 mm²		
Koneksi		

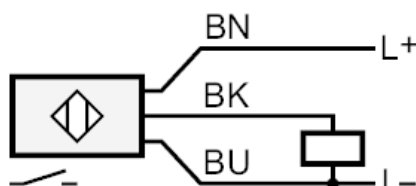

BN = Warna core :
 BK = coklat
 BU = biru
 hitam