


IG-4005ZCPKG/20M/SH

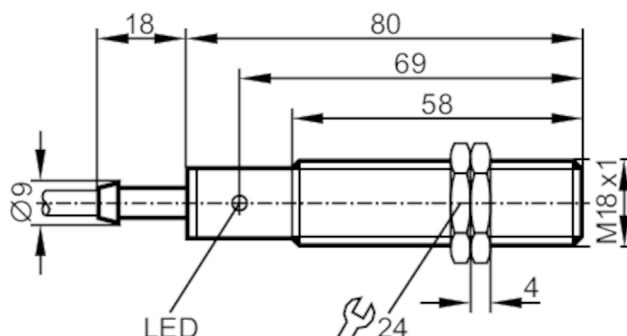



Sensor induktif

IG-4005ZCPKG/20M/SH

Histeresis	[X01]	3...15
Deviasi titik peralihan	[X01]	-10...10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...100
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B

Data teknis

Casing		tipe berulir
Pemasangan		flush mountable
Dimensi	[mm]	M18 x 1 / L = 80
Penamaan ulir		M18 x 1
Material		PBT

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Aksesori

Item dikirim		mur pengunci: 2
--------------	--	-----------------


Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 20 m, silikon; 4 x 0.34 mm²

Koneksi

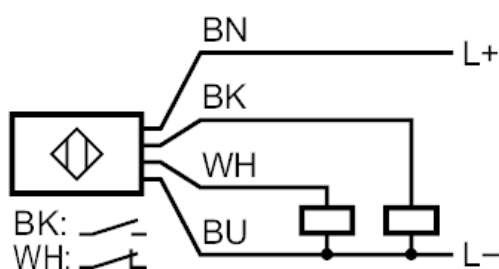

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih