


IG-3008-BPKG/10M




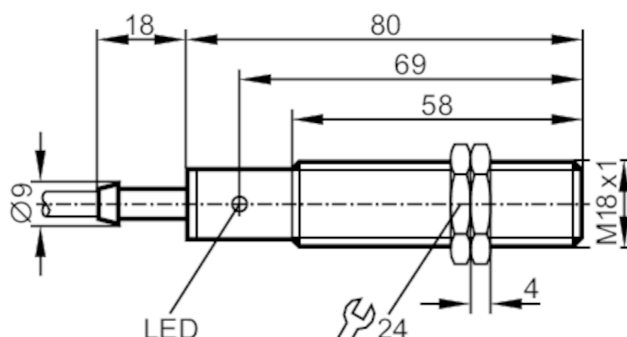

Sensor induktif

IG-3008-BPKG/10M

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Pengujian/persetujuan		
EME	EN 60947-5-2	
MTTF	[ANN]	1853
Data teknis		
Berat	[g]	490
Casing		tipe berulir
Pemasangan		non-flush mountable
Dimensi	[mm]	M18 x 1 / L = 80
Penamaan ulir		M18 x 1
Material		PBT
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim		mur pengunci: 2
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 10 m, PVC; 3 x 0.5 mm ²		
Koneksi		

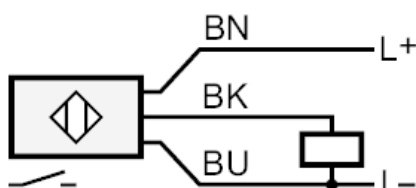

BN = Warna core :
 BU = coklat
 BK = biru
 hitam