


IGA3008-ANKG




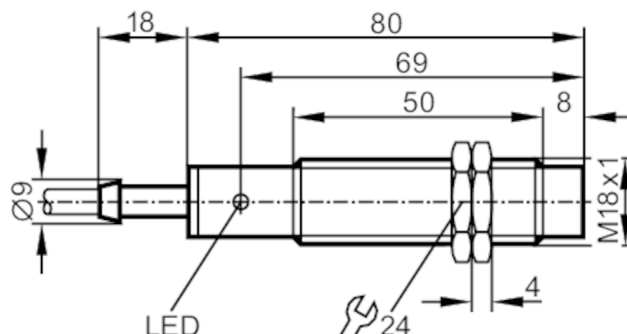

Sensor induktif

IGA3008-ANKG

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Pengujian/persetujuan		
EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	1754
Data teknis		
Berat	[g]	160.1
Casing		tipe berulir
Pemasangan		non-flush mountable
Dimensi	[mm]	M18 x 1 / L = 80
Penamaan ulir		M18 x 1
Material		kuningan dilapisi perunggu putih; PC
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim		mur pengunci: 2
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 2 m, PVC; 3 x 0.5 mm ²		
Koneksi		

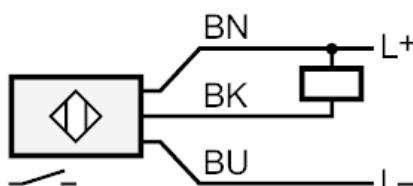

BN = Warna core :
 BK = coklat
 BU = biru
 hitam