

RT



Sensor induktif

II-3015-APKG

RT

Jarak pengoperasian	[mm]	0...12.1
---------------------	------	----------

Akurasi/deviasi

Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2	
Histeresis	[X01]	1...15
Deviasi titik peralihan	[X01]	-10...10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B

Data teknis

Casing		tipe berulir
Pemasangan		non-flush mountable
Dimensi	[mm]	M30 x 1.5 / L = 81
Penamaan ulir		M30 x 1.5
Material		PBT

Elemen display/pengoperasian

Display	status peralihan	1 x LED, merah
---------	------------------	----------------

Aksesori

Item dikirim		mur pengunci: 2
--------------	--	-----------------


Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 2 m, PVC; 3 x 0.5 mm²

Koneksi

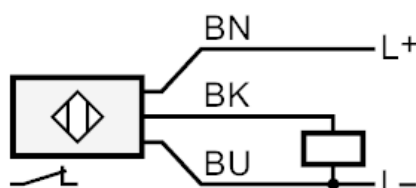

Warna core :
 BK = hitam
 BN = coklat
 BU = biru