




Sensor induktif

IMC2015-ARKG/0,15/PUR/US

Produk tidak tersedia - entri arsip

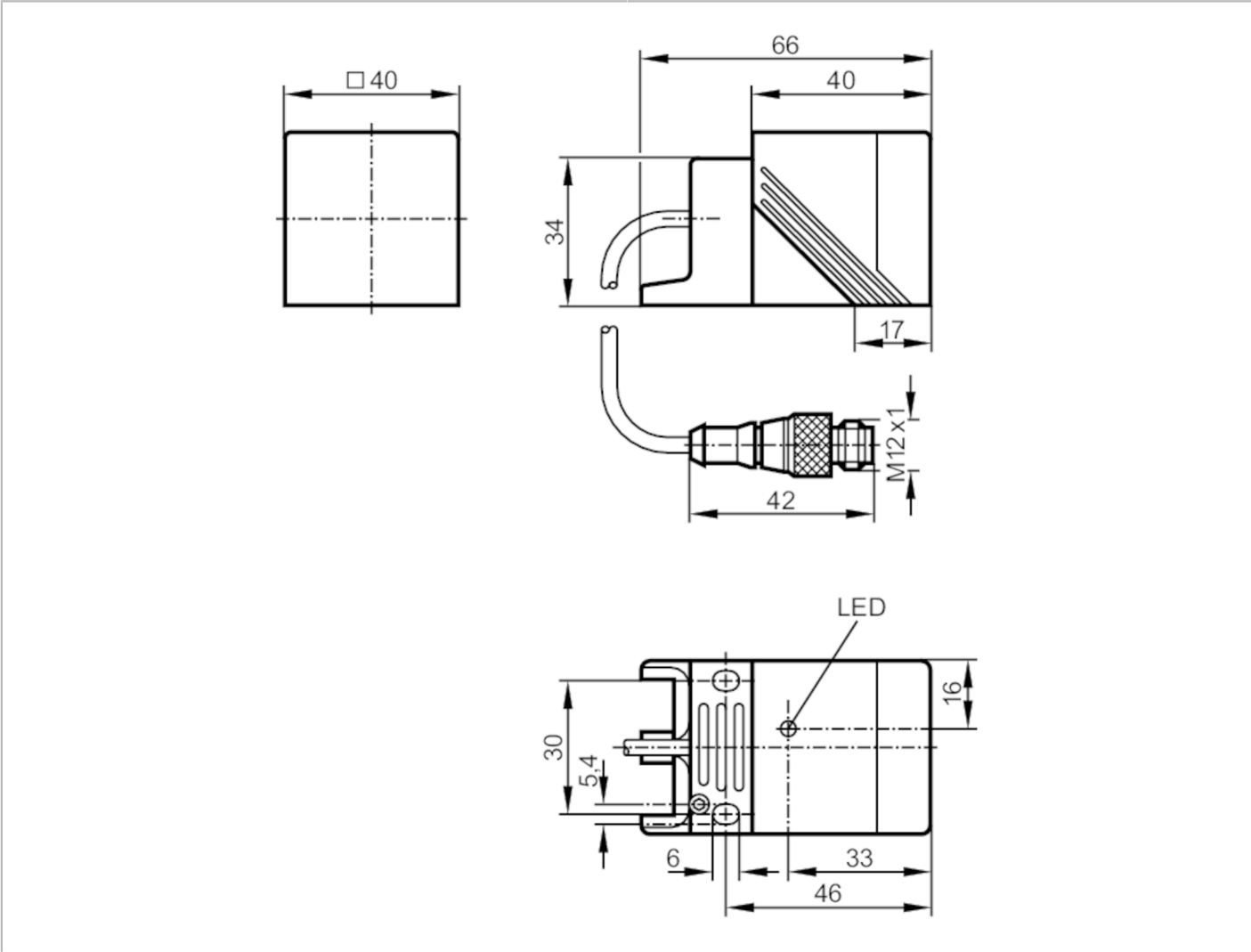

Karakteristik produk	
Desain kelistrikan	PNP/NPN
Fungsi output	biasanya terbuka
Jangkauan pendeteksian [mm]	15
Casing	persegi panjang
Dimensi [mm]	40 x 40 x 66
Aplikasi	
Fitur khusus	Kontak berlapis emas
Data kelistrikan	
Tegangan pengoperasian [V]	10...55 DC
Pelindung polaritas terbalik	ya
Output	
Desain kelistrikan	PNP/NPN
Fungsi output	biasanya terbuka



Sensor induktif

IMC2015-ARKG/0,15/PUR/US

Penurunan tegangan maks. pada output peralihan DC	[V]	4.6
Arus beban minimal	[mA]	4
Kebocoran arus maks.	[mA]	0.8
Peringkat arus permanen dari output peralihan DC	[mA]	100
Frekuensi peralihan DC	[Hz]	150
Pelindung hubung singkat		ya
Tipe pelindung hubung singkat		berpulsa
Pelindung beban berlebih		ya

Zona pendeteksian

Jangkauan pendeteksian	[mm]	15
Jangkauan pendeteksian real Sr	[mm]	15 ± 10 %
Jarak pengoperasian	[mm]	0...12.1

Akurasi/deviasi

Faktor koreksi		baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2
Histeresis	[X01]	1...15
Deviasi titik peralihan	[X01]	-10...10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...70
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B

Data teknis

Casing		persegi panjang
Pemasangan		flush mountable
Dimensi	[mm]	40 x 40 x 66
Material		casing: PBT; permukaan pendeteksian: PEI; klem: PPS

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Aksesori

Item dikirim		Braket pemasangan: 1
		Kunci pas: 1

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Sensor induktif

IMC2015-ARKG/0,15/PUR/US

Koneksi listrik - colokan

Kabel: 0.15 m, PUR

Konektor: 1 x M12; pengkodean: A; Kontak: dilapisi emas



Koneksi

