

IN5145



Sensor induktif

IN-3002-APKG/6M

Jangkauan pendeteksian real [mm] Sr	2 ± 10 %
Jarak pengoperasian [mm]	0...1.6

Akurasi/deviasi	
Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2
Histeresis [X01]	1...15
Deviasi titik peralihan [X01]	-10...10

Kondisi pengoperasian	
Suhu sekitar [°C]	-25...80
Perlindungan	IP 67

Pengujian/persetujuan	
EME	EN 60947-5-2

Data teknis	
Casing	persegi panjang
Pemasangan	flush mountable
Dimensi [mm]	40 x 12 x 26
Material	PBT


Lubang pemasangan	
Torsi pengencangan [Nm]	< 0.5

Bushing berulir	
Torsi pengencangan [Nm]	< 1.2; (ketika insert kuningan bersentuhan dengan pasangan komponen)

Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning

Keterangan	
Jumlah paket	1 buah

Koneksi listrik	
Kabel: 6 m, PVC; 3 x 0.5 mm²	
Koneksi	

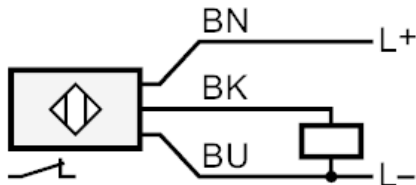

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru