




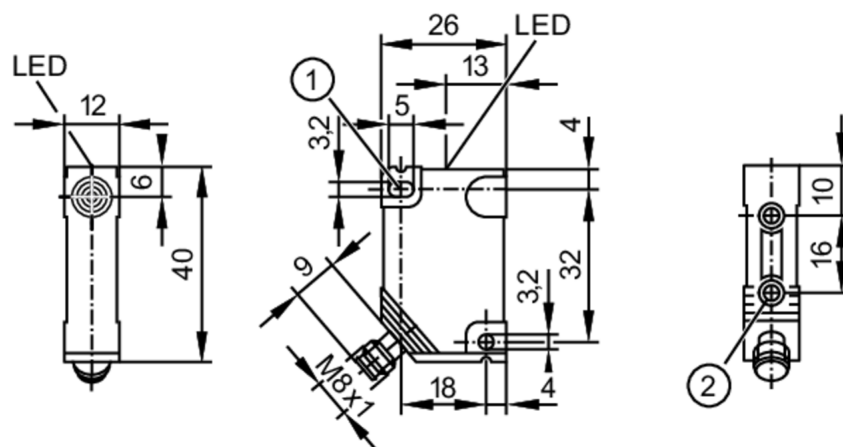

Sensor induktif

IN-2004-FRKG/AS-610-T

Jarak pengoperasian	[mm]	0...3.25
Akurasi/deviasi		
Faktor koreksi		baja: 1 / baja tahan karat: 0.7 / kuningan: 0.4 / aluminium: 0.3 / tembaga: 0.2
Histeresis	[X01]	1...15
Deviasi titik peralihan	[X01]	-10...10
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 65
Pengujian/persetujuan		
EME		EN 60947-5-2
		EN 55011 kelas B
MTTF	[ANN]	1645
Persetujuan UL	Ta	0...40 °C
	Tipe penutup	Type 1
	suplai tegangan	Hazardous voltage
	Nomor file UL	E174191
Data teknis		
Berat	[g]	21
Casing		persegi panjang
Pemasangan		non-flush mountable
Dimensi	[mm]	40 x 12 x 26
Material		PBT
Lubang pemasangan		
Torsi pengencangan	[Nm]	< 0.5
Bushing berulir		
Torsi pengencangan	[Nm]	< 1.2; (ketika insert kuningan bersentuhan dengan pasangan komponen)
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, merah
Keterangan		
Jumlah paket		1 buah

IN5258



Sensor induktif

IN-2004-FRKG/AS-610-T

Koneksi listrik - colokan

Konektor: 1 x M8; pengkodean: A

