


Sensor ganda induktif untuk aktuatur katup

IND2004DARKG/US-100-ZRV RT

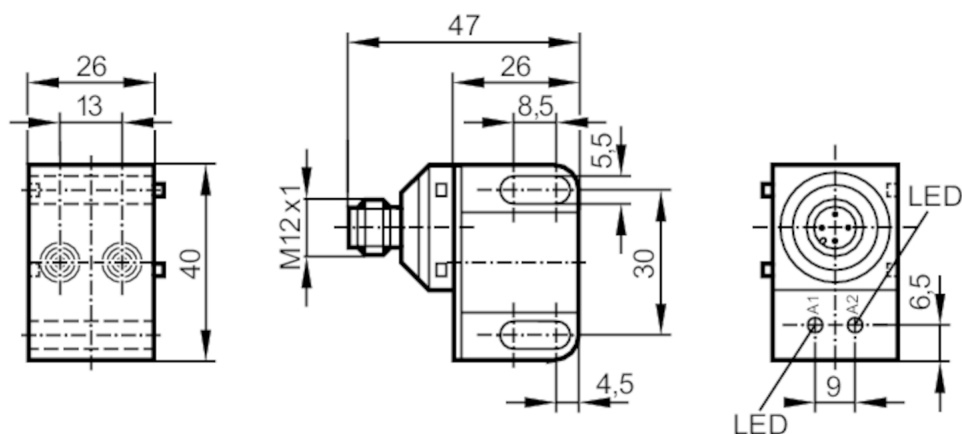

Karakteristik produk

Desain kelistrikan	PNP/NPN
Fungsi output	2 x biasanya terbuka
Jangkauan pendeteksian [mm]	4
Casing	persegi panjang
Dimensi [mm]	40 x 26 x 47

Data kelistrikan

Tegangan pengoperasian [V]	10...36 DC
Kelas perlindungan	II
Pelindung polaritas terbalik	ya

Output

Desain kelistrikan	PNP/NPN
Fungsi output	2 x biasanya terbuka
Penurunan tegangan maks. pada output peralihan DC [V]	4
Arus beban minimal [mA]	4
Kebocoran arus maks. [mA]	2 x 0.7
Peringkat arus permanen dari output peralihan DC [mA]	250
Frekuensi peralihan DC [Hz]	250
Pelindung hubung singkat	ya
Tipe pelindung hubung singkat	berpulsa
Pelindung beban berlebih	ya

Zona pendeteksian

Jangkauan pendeteksian [mm]	4
Jangkauan pendeteksian real Sr	4 ± 10 %
Jarak pengoperasian [mm]	0...3.25

Akurasi/deviasi

Faktor koreksi	baja: 1 / baja tahan karat: 0.7 / aluminium: 0.3 / tembaga: 0.4
----------------	---



Sensor ganda induktif untuk aktuatur katup

IND2004DARKG/US-100-ZRV RT

Histeresis	[X01]	3...15
Deviasi titik peralihan	[X01]	-10...10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
MTTF	[ANN]	1229

Data teknis

Berat	[g]	58.5
Casing		persegi panjang
Pemasangan		non-flush mountable
Dimensi	[mm]	40 x 26 x 47
Material		casing: PBT; penutup: PC

Elemen display/pengoperasian

Display	status peralihan	2 x LED, merah
---------	------------------	----------------

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: kuningan, dilapisi perunggu putih



Koneksi

