


Sensor induktif

IZB30,8-BPKG/V2A/AS-514-TPS RT

penghentian produk

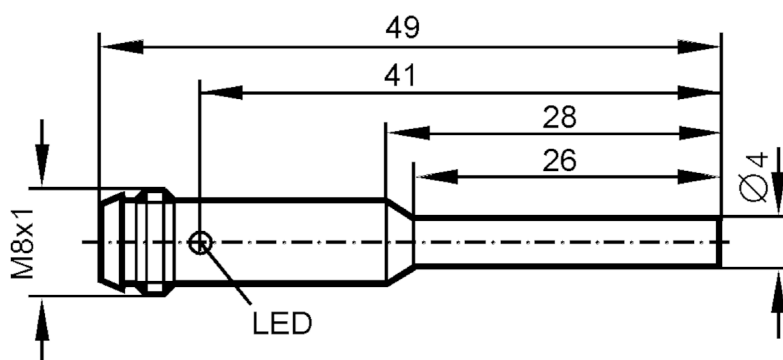

Karakteristik produk

Desain kelistrikan	PNP
Fungsi output	biasanya terbuka
Jangkauan pendeteksian [mm]	0.8
Casing	berbentuk silinder
Dimensi [mm]	Ø 4

Data kelistrikan

Tegangan pengoperasian [V]	10...36 DC
Konsumsi arus [mA]	15; (24 V)
Kelas perlindungan	III
Pelindung polaritas terbalik	ya

Output

Desain kelistrikan	PNP
Fungsi output	biasanya terbuka
Penurunan tegangan maks. pada output peralihan DC [V]	2.5
Peringkat arus permanen dari output peralihan DC [mA]	100
Frekuensi peralihan DC [Hz]	800
Pelindung hubung singkat	ya
Tipe pelindung hubung singkat	berpulsa
Pelindung beban berlebih	ya



Sensor induktif

IZB30,8-BPKG/V2A/AS-514-TPS RT

Zona pendeteksian		
Jangkauan pendeteksian	[mm]	0.8
Jangkauan pendeteksian real Sr	[mm]	0.8 ± 10 %
Jarak pengoperasian	[mm]	0...0.65
Akurasi/deviasi		
Faktor koreksi		baja: 1 / baja tahan karat: 0.7 / kuningan: 0.5 / aluminium: 0.4 / tembaga: 0.3
Histeresis	[X01]	3...15
Deviasi titik peralihan	[X01]	-10...10
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 65
Pengujian/persetujuan		
EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	953
Data teknis		
Berat	[g]	13.2
Casing		berbentuk silinder
Pemasangan		flush mountable
Dimensi	[mm]	Ø 4
Material		baja tahan karat (1.4305/303); LCP
Elemen display/pengoperasian		
Display	status peralihan	4 x 90° LED, merah
Aksesori		
Item dikirim		Klem pemasangan: 1
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M8; pengkodean: A



IZ5034



Sensor induktif

IZB30,8-BPKG/V2A/AS-514-TPS RT

Koneksi

