


MK5137



Sensor silinder T-slot

MKT3020BANKG//A/0,3M/ZH/AS

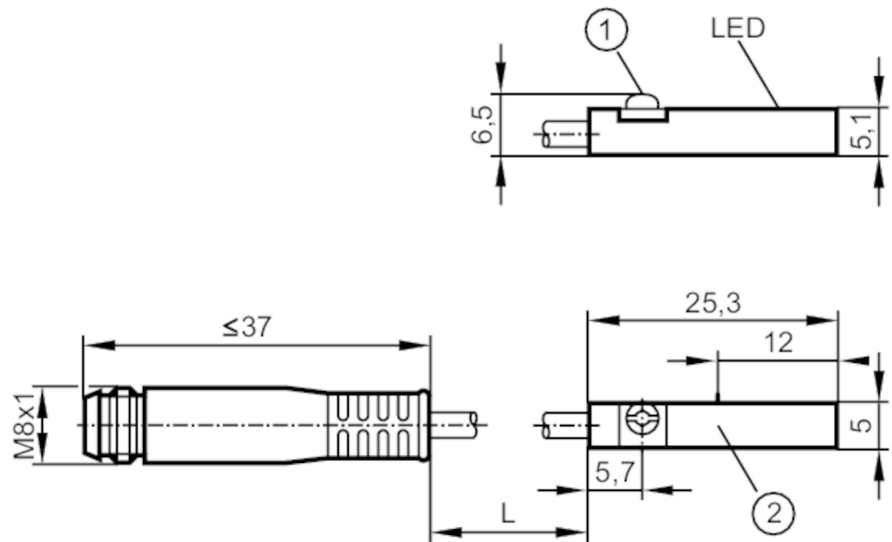

- 1 klem pengencang
2 permukaan pendeteksian



Karakteristik produk

Desain kelistrikan	NPN
Fungsi output	biasanya terbuka
Dimensi [mm]	25 x 5 x 6.5

Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC; ("kelas suplai 2" menurut cULus)
Konsumsi arus [mA]	< 10
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Waktu penundaan pengaktifan maks. [ms]	30

Output

Desain kelistrikan	NPN
Fungsi output	biasanya terbuka
Penurunan tegangan maks. pada output peralihan DC [V]	2.5
Peringkat arus permanen dari output peralihan DC [mA]	100
Frekuensi peralihan DC [Hz]	6000
Pelindung hubung singkat	ya
Pelindung beban berlebih	ya

Zona pendeteksian

Sensitivitas respons [mT]	2
Kecepatan pergerakan [m/s]	> 10

Akurasi/deviasi

Histeresis [mm]	< 1
-----------------	-----



Sensor silinder T-slot

MKT3020BANKG//A/0,3M/ZH/AS

Kemampuan pengulangan	[mm]	< 0.2
-----------------------	------	-------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
--------------	------	----------

Perlindungan		IP 65; IP 67
--------------	--	--------------

Pengujian/persetujuan

EME	EN 61000-4-2 ESD	- CD / 8 kV AD
	EN 61000-4-3 HF dipancarkan	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF dihantarkan	10 V
	EN 55011	kelas B

MTTF	[ANN]	2076
------	-------	------

Persetujuan UL	Persetujuan UL no.	C003
----------------	--------------------	------

Data teknis

Berat	[g]	14.5
-------	-----	------

Pemasangan		flush mountable
------------	--	-----------------

Tipe pemasangan		klem pengencang dengan slot kombinasi/soket segienam, lebar penampang 1,5
-----------------	--	---

Tipe silinder		Silinder T-slot
---------------	--	-----------------

Dimensi	[mm]	25 x 5 x 6.5
---------	------	--------------

Material		casing: PA; klem pengencang: baja tahan karat
----------	--	---

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Aksesori

Item dikirim		placeholder karet: 1
--------------	--	----------------------

		Klip kabel: 1
--	--	---------------

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik - colokan

Kabel: 0.3 m, PUR

Konektor: 1 x M8; pengkodean: A; Penguncian: snap-fit



Sensor silinder T-slot

MKT3020BANKG//A/0,3M/ZH/AS

Koneksi

