


Pencahaya external

BACKLIGHT 50X50 IR/0,3M/US

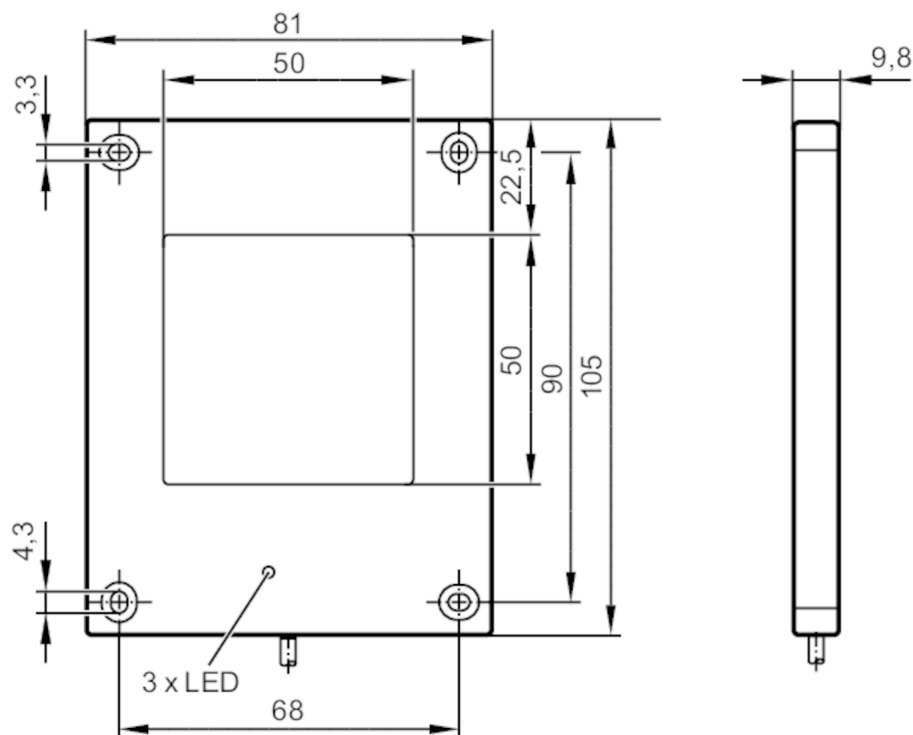

Karakteristik produk

Tipe cahaya	cahaya inframerah
-------------	-------------------

Aplikasi

Fitur khusus	Kontak berlapis emas
Area yang diterangi [mm]	50 x 50
Desain	lampu latar
Tipe operasi	Operasi cahaya atau pulsa permanen

Data kelistrikan

Toleransi tegangan pengoperasian [%]	-10...10
Tegangan pengoperasian [V]	24 DC
Konsumsi arus [mA]	< 325
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Tipe cahaya	cahaya inframerah
Panjang gelombang [nm]	875

Input

Pemicu	5...24 V
--------	----------

Kondisi pengoperasian

Suhu sekitar [°C]	-10...50
Perlindungan	IP 54



Pencahayaan eksternal

BACKLIGHT 50X50 IR/0,3M/US

Pelindung panas berlebih	ya; (> 50 °C)
--------------------------	---------------

Pengujian/persetujuan

Keamanan fotobiologis	pisahkan grup; (EN 62471)
MTTF [ANN]	309

Data teknis

Berat [g]	264.4
Dimensi [mm]	105 x 81 x 9.8
Material	aluminium
Material lensa	kaca

Elemen display/pengoperasian

Display	status pencahayaan	1 x LED, kuning
	operasi	1 x LED, hijau
	suhu yang berlebihan/kelebihan beban	1 x LED, merah

Keterangan

Jumlah paket	1 buah
--------------	--------


Koneksi listrik

Kabel: 0.30 m, PUR

Konektor: 1 x M12; pengkodean: A; Kontak: dilapisi emas



Koneksi

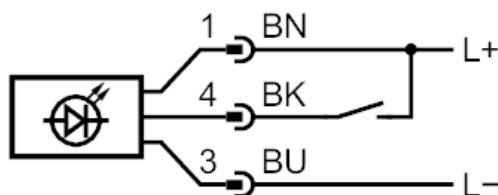

1	L +
3	L -
4	pemicu
	Warna core :
BK =	hitam
BN =	coklat
BU =	biru