


Pencahaya eksternal

BACKLIGHT 100X100 IR/0,3M/US

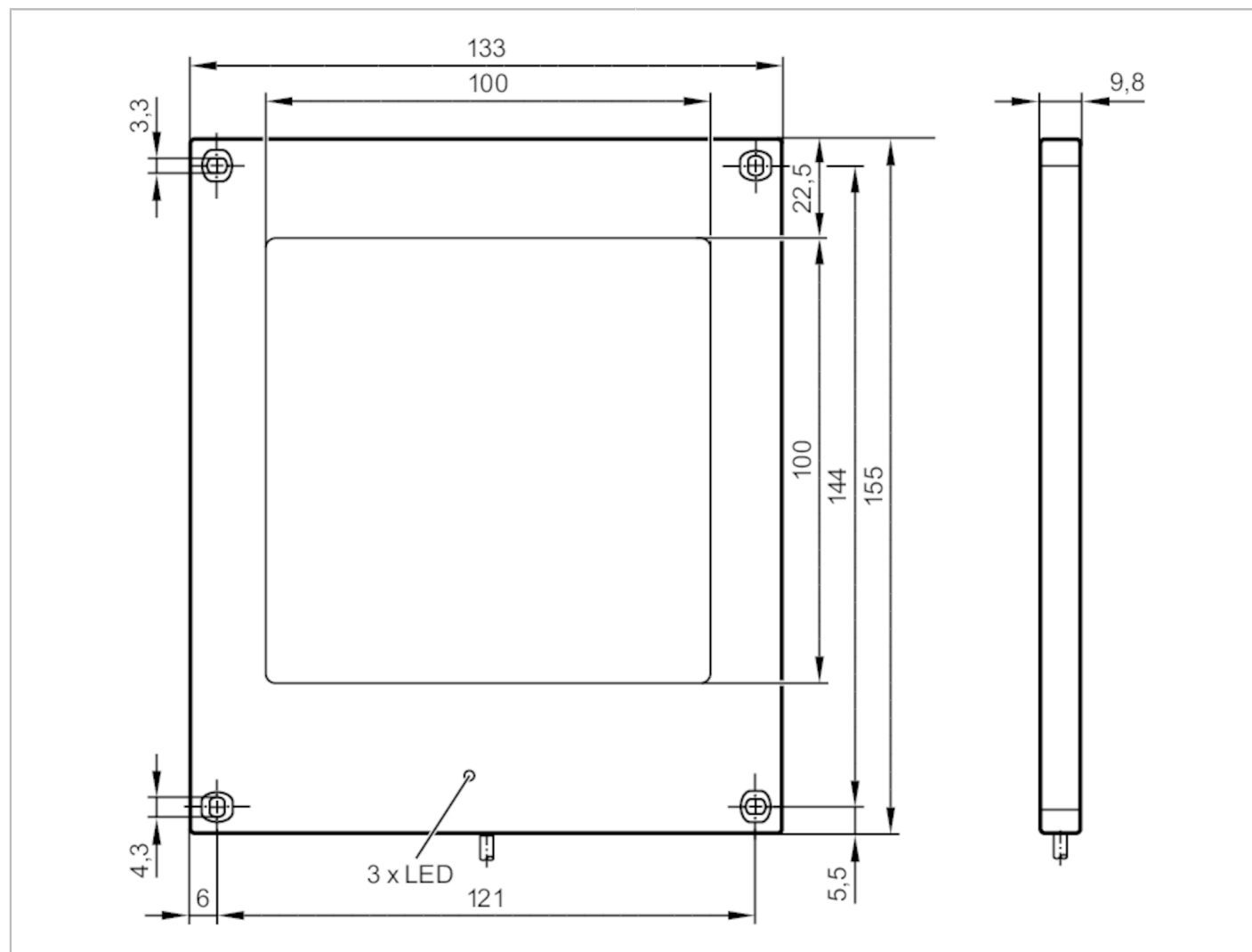

Karakteristik produk

Tipe cahaya	cahaya inframerah
-------------	-------------------

Aplikasi

Fitur khusus	Kontak berlapis emas
Area yang diterangi [mm]	100 x 100
Desain	lampu latar
Tipe operasi	Operasi cahaya atau pulsa permanen

Data kelistrikan

Toleransi tegangan pengoperasian [%]	-10...10
Tegangan pengoperasian [V]	24 DC
Konsumsi arus [mA]	< 620
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Tipe cahaya	cahaya inframerah
Panjang gelombang [nm]	875




Pencahayaan eksternal

BACKLIGHT 100X100 IR/0,3M/US

Input		
Pemicu		5...24 V
Output		
Pelindung beban berlebih		ya
Kondisi pengoperasian		
Suhu sekitar	[°C]	-10...50
Perlindungan		IP 54
Pelindung panas berlebih		ya; (> 50 °C)
Pengujian/persetujuan		
Keamanan fotobiologis		pisahkan grup; (EN 62471)
MTTF	[ANN]	293
Data teknis		
Berat	[g]	448.4
Dimensi	[mm]	155 x 133 x 9.8
Material		aluminium
Material lensa		kaca
Elemen display/pengoperasian		
Display	status pencahayaan	1 x LED, kuning
	operasi	1 x LED, hijau
	suhu yang berlebihan/kelebihan beban	1 x LED, merah
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 0.3 m, PUR		
Konektor: 1 x M12; pengkodean: A; Kontak: dilapisi emas		
		

Pencahayaan eksternal

BACKLIGHT 100X100 IR/0,3M/US

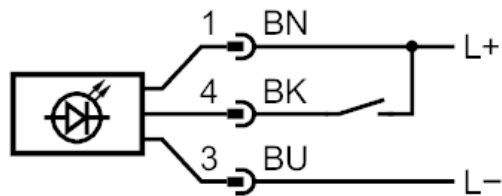Koneksi

1	L +
3	L -
4	pemicu
Warna core :	
BK =	hitam
BN =	coklat
BU =	biru