


O7P-HPKG/0,20M/AS

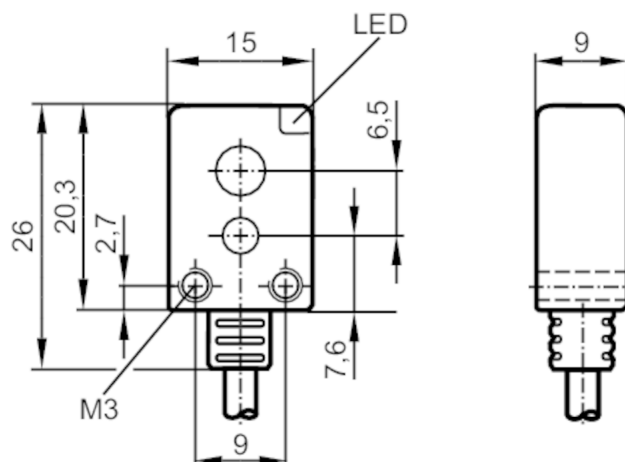

receiver di lensa atas
transmitter di lensa bawah





Sensor retro-reflektif

O7P-HPKG/0,20M/AS

Jangkauan yang dapat disesuaikan	tidak
Diameter titik cahaya maks. [mm]	55
Dimensi titik cahaya mengacu pada	pada jangkauan maksimum
Tersedia filter polarisasi	ya

Kondisi pengoperasian

Suhu sekitar [°C]	-25...60
Perlindungan	IP 65

Pengujian/persetujuan

EME	EN 60947-5-2
MTTF [ANN]	1155

Data teknis

Berat [g]	14.4
Casing	persegi panjang
Dimensi [mm]	20.3 x 15 x 9
Material	PA
Material lensa	PMMA
Penyelarasan lensa	lensa samping

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
---------	------------------	-----------------

Keterangan

Keterangan	tegangan pengoperasian "kelas suplai 2" menurut UL
Jumlah paket	1 buah

Koneksi listrik

Kabel: 0.2 m, PUR; 3 x 0.14 mm²

Konektor: 1 x M8; pengkodean: A; Penguncian: snap-fit



O7P201



Sensor retro-reflektif

O7P-HPKG/0,20M/AS

Koneksi

