


OAS-0000A

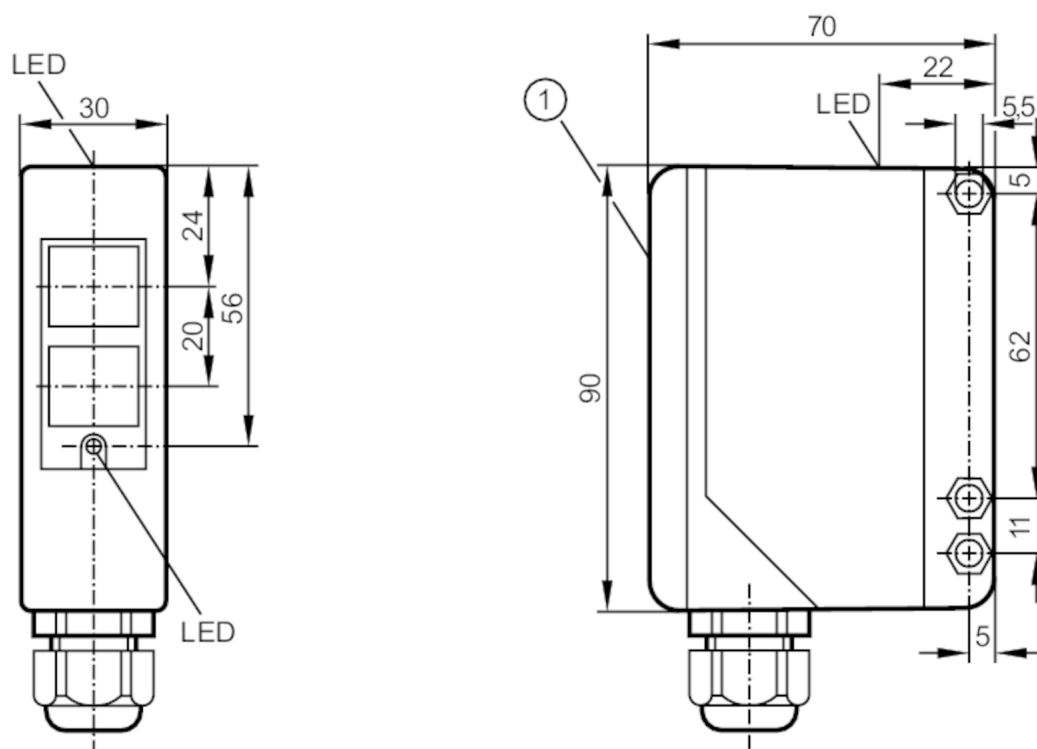

- CCC CE cUL US UK
LISTED CA

Zona pendeteksian	
Transmitter/receiver	transmitter
Jarak jangkauan [m]	< 50
Jangkauan yang dapat disesuaikan	tidak



Transmitter sensor sinar tembus

OAS-000A

Diameter titik cahaya maks. [mm]	1500
Dimensi titik cahaya mengacu pada	pada jangkauan maksimum

Kondisi pengoperasian

Suhu sekitar [°C]	-25...60
Perlindungan	IP 65

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF [ANN]	393	

Data teknis

Berat [g]	278
Casing	persegi panjang
Dimensi [mm]	90 x 30 x 70
Material	PPO dimodifikasi
Material lensa	PMMA
Penyelarasan lensa	lensa samping

Elemen display/pengoperasian

Display	operasi	1 x LED, hijau
---------	---------	----------------

Aksesori

Item dikirim	Braket siku: 1, E20514
	obeng

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

terminal: ...1.5 mm²; Selubung kabel: Ø 4.5...10 mm; Konektor kabel: M16 X 1.5

Koneksi

