


OGE-DPKG/6M




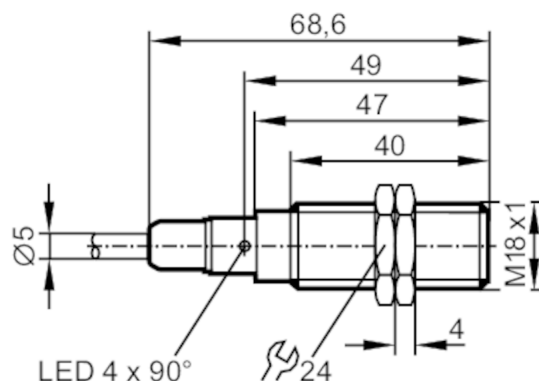

Receiver sensor sinar tembus

OGE-DPKG/6M

Pengujian/persetujuan		
EME	EN 60947-5-2	
MTTF	[ANN]	1112
Data teknis		
Berat	[g]	255.8
Casing		tipe berulir
Dimensi	[mm]	M18 x 1 / L = 68.6
Penamaan ulir		M18 x 1
Material		casing: baja tahan karat (1.4404 / 316L); Segel: EPDM
Material lensa		PMMA
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim		mur pengunci: 2
Keterangan		
Keterangan		tegangan pengoperasian "kelas suplai 2" menurut cULus
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 6 m, PVC; 3 x 0.34 mm ²		
Koneksi		

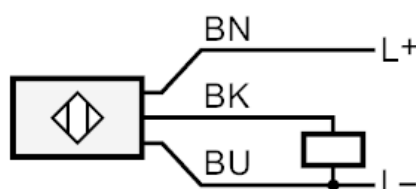

BK = Warna core :
 hitam
 BN = coklat
 BU = biru

Receiver sensor sinar tembus

OGE-DPKG/6M

Diagram dan grafik

grafik excess gain

