

Transmitter sensor sinar tembus

OGS-000W/LS/CUBE

Produk tidak tersedia - entri arsip



Karakteristik produk

Tipe cahaya	cahaya merah
Casing	rectangular with M18 thread

Aplikasi

Prinsip fungsi	Sensor sinar tembus
----------------	---------------------

Data kelistrikan

Frekuensi AC	[Hz]	47...60
Tegangan pengoperasian	[V]	20...250 AC
Konsumsi arus	[mA]	< 5
Kelas perlindungan		II; (double insulated)
Tipe cahaya		cahaya merah
Panjang gelombang	[nm]	633

Zona pendeteksian

Transmitter/receiver		transmitter
Jarak jangkauan	[m]	< 20
Jangkauan yang dapat disesuaikan		tidak
Diameter titik cahaya maks.	[mm]	800
Dimensi titik cahaya mengacu pada		pada jangkauan maksimum

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
Perlindungan		IP 67

Pengujian/persetujuan

EME	EN 60947-5-2	
	EN 55011 emisi	kelas B



Transmitter sensor sinar tembus

OGS-000W/LS/CUBE

Data teknis		
Berat	[g]	59.5
Casing		rectangular with M18 thread
Dimensi	[mm]	52.6 x 19.1 x 36.9
Penamaan ulir		M18 x 1
Material		seng tuang; PEI
Material lensa		PMMA
Penyelarasan lensa		lensa samping

Elemen display/pengoperasian		
Display	operasi	1 x LED, hijau

Koneksi listrik	
Perlindungan yang diperlukan	sekring miniatur sesuai IEC60127-2 lembar 1; ≤ 2 A; cepat

Aksesori	
Item dikirim	mur pengunci: 1

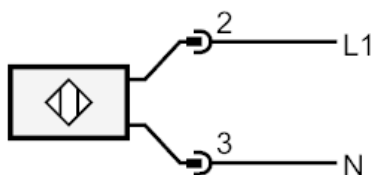
Keterangan	
Jumlah paket	1 buah

Koneksi listrik	
-----------------	--

Konektor: 1 x 1/2"; pengkodean: C



Koneksi	
---------	--

Catatan : sekring miniatur sesuai IEC60127-2 lembar 1 ≤ 2 A cepat