




Transmitter sensor sinar tembus

OJS-OOKG/FO/0,15M/US

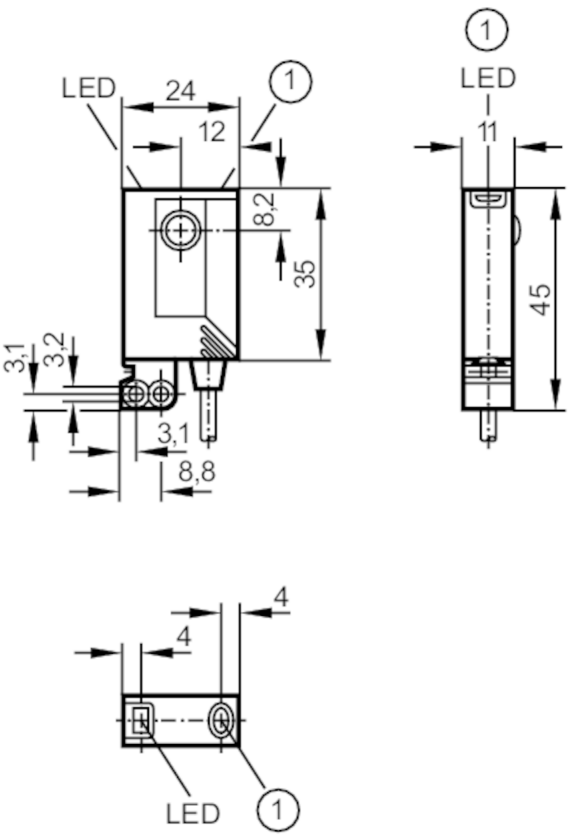

1 tombol tekan tanpa fungsi



| Karakteristik produk         |      |                      |
|------------------------------|------|----------------------|
| Tipe cahaya                  |      | cahaya merah         |
| Casing                       |      | persegi panjang      |
| Aplikasi                     |      |                      |
| Fitur khusus                 |      | Kontak berlapis emas |
| Prinsip fungsi               |      | Sensor sinar tembus  |
| Data kelistrikan             |      |                      |
| Tegangan pengoperasian       | [V]  | 10...30 DC           |
| Konsumsi arus                | [mA] | < 19                 |
| Kelas perlindungan           |      | III                  |
| Pelindung polaritas terbalik |      | ya                   |
| Tipe cahaya                  |      | cahaya merah         |
| Panjang gelombang            | [nm] | 660                  |
| Output                       |      |                      |
| Pelindung beban berlebih     |      | ya                   |
| Zona pendeteksian            |      |                      |
| Transmitter/receiver         |      | transmitter          |
| Jarak jangkauan              | [m]  | < 10                 |



## Transmitter sensor sinar tembus

OJS-00KG/FO/0,15M/US

|                                                                                                                                  |                                                                              |
|----------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------|
| Diameter titik cahaya maks. [mm]                                                                                                 | 1000                                                                         |
| Dimensi titik cahaya mengacu pada                                                                                                | pada jangkauan maksimum                                                      |
| <b>Kondisi pengoperasian</b>                                                                                                     |                                                                              |
| Suhu sekitar [°C]                                                                                                                | -25...60                                                                     |
| Perlindungan                                                                                                                     | IP 67                                                                        |
| <b>Pengujian/persetujuan</b>                                                                                                     |                                                                              |
| EME                                                                                                                              | EN 60947-5-2                                                                 |
| MTTF [ANN]                                                                                                                       | 1773                                                                         |
| <b>Data teknis</b>                                                                                                               |                                                                              |
| Berat [g]                                                                                                                        | 52.05                                                                        |
| Casing                                                                                                                           | persegi panjang                                                              |
| Dimensi [mm]                                                                                                                     | 35 x 24 x 11                                                                 |
| Material                                                                                                                         | casing: ABS; perlengkapan: seng tuang; Jendela LED: SEPS; tombol tekan: SEPS |
| Material lensa                                                                                                                   | kaca                                                                         |
| Penyelarasan lensa                                                                                                               | lensa depan                                                                  |
| <b>Elemen display/pengoperasian</b>                                                                                              |                                                                              |
| Display                                                                                                                          | operasi 1 x LED, hijau                                                       |
| <b>Aksesori</b>                                                                                                                  |                                                                              |
| Item dikirim                                                                                                                     | Klip dasar: 1, E20964                                                        |
|                                                                                                                                  | sekrup: 2 x M3 x 16                                                          |
|                                                                                                                                  | Washer pegas: 2                                                              |
|                                                                                                                                  | Mur: 2                                                                       |
| <b>Keterangan</b>                                                                                                                |                                                                              |
| Keterangan                                                                                                                       | tegangan pengoperasian "kelas suplai 2" menurut cULus                        |
| Jumlah paket                                                                                                                     | 1 buah                                                                       |
| <b>Koneksi listrik</b>                                                                                                           |                                                                              |
| Kabel: 0.15 m, PVC                                                                                                               |                                                                              |
| Konektor: 1 x M12; pengkodean: A; Bodi cetakan: Hytrel 8068; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas |                                                                              |
|                                                                                                                                  |                                                                              |

# OJ5065



## Transmitter sensor sinar tembus

OJS-OOKG/FO/0,15M/US

### Koneksi

