




Transmitter sensor sinar tembus

OJS-OOKG/FO/AS

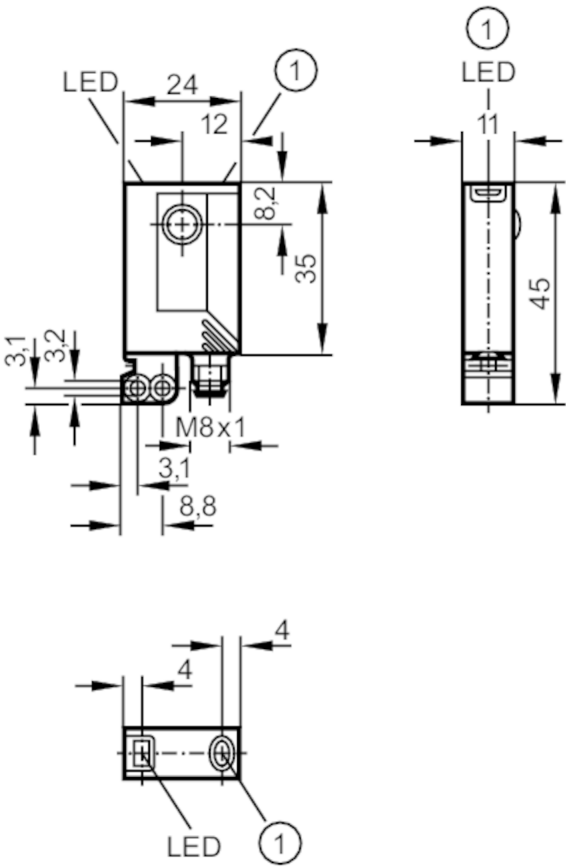

1 tombol tekan tanpa fungsi



Karakteristik produk		
Tipe cahaya		cahaya inframerah
Casing		persegi panjang
Aplikasi		
Prinsip fungsi		Sensor sinar tembus
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Konsumsi arus	[mA]	< 19
Kelas perlindungan		III
Pelindung polaritas terbalik		ya
Tipe cahaya		cahaya inframerah
Panjang gelombang	[nm]	880
Output		
Pelindung beban berlebih		ya
Zona pendeteksian		
Transmitter/receiver		transmitter



Transmitter sensor sinar tembus

OJS-OOKG/FO/AS

Jarak jangkauan	[m]	< 5
-----------------	-----	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
--------------	------	----------

Perlindungan		IP 67
--------------	--	-------

Pengujian/persetujuan

EME		EN 60947-5-2
-----	--	--------------

MTTF	[ANN]	1759
------	-------	------

Data teknis

Berat	[g]	26.6
-------	-----	------

Casing		persegi panjang
--------	--	-----------------

Dimensi	[mm]	35 x 24 x 11
---------	------	--------------

Material		casing: ABS; perlengkapan: seng tuang; Jendela LED: SEPS; tombol tekan: SEPS
----------	--	--

Material lensa		kaca
----------------	--	------

Penyelarasan lensa		lensa depan
--------------------	--	-------------

Elemen display/pengoperasian

Display	operasi	1 x LED, hijau
---------	---------	----------------

Aksesori

Item dikirim		Klip dasar: 1, E20964
--------------	--	-----------------------

		sekrup: 2 x M3 x 16
--	--	---------------------

		Washer pegas: 2
--	--	-----------------

		Mur: 2
--	--	--------

Keterangan

Keterangan		tegangan pengoperasian "kelas suplai 2" menurut cULus
------------	--	---

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Konektor: 1 x M8; pengkodean: A





Transmitter sensor sinar tembus

OJS-00KG/FO/AS

Koneksi

