


Transmitter sensor sinar tembus

OJS-OOKG/FO/AS

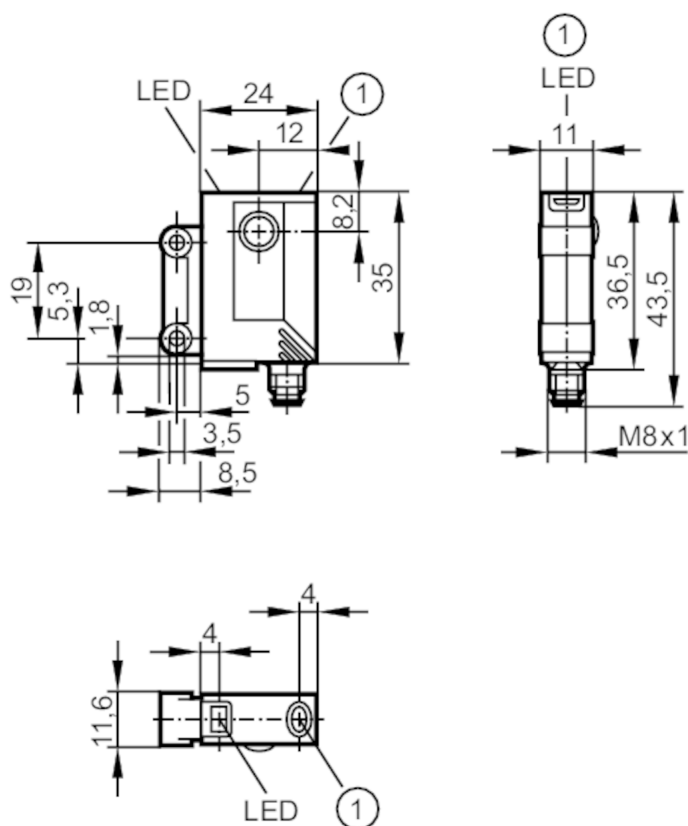

1 tombol tekan tanpa fungsi



Karakteristik produk

Tipe cahaya	cahaya merah
Casing	persegi panjang

Aplikasi

Prinsip fungsi	Sensor sinar tembus
----------------	---------------------

Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC
Konsumsi arus [mA]	< 19
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Tipe cahaya	cahaya merah
Panjang gelombang [nm]	660

Output

Pelindung beban berlebih	ya
--------------------------	----

Zona pendeteksian

Transmitter/receiver	transmitter
Jarak jangkauan [m]	< 10
Diameter titik cahaya maks. [mm]	1000



Transmitter sensor sinar tembus

OJS-OOKG/FO/AS

Dimensi titik cahaya mengacu pada	pada jangkauan maksimum
-----------------------------------	-------------------------

Kondisi pengoperasian

Suhu sekitar [°C]	-25...60
Perlindungan	IP 67

Pengujian/persetujuan

EME	EN 60947-5-2
MTTF [ANN]	1773

Data teknis

Berat [g]	26.95
Casing	persegi panjang
Dimensi [mm]	35 x 24 x 11
Material	casing: ABS; perlengkapan: seng tuang; Jendela LED: SEPS; tombol tekan: SEPS
Material lensa	kaca
Penyelarasan lensa	lensa depan

Elemen display/pengoperasian

Display	operasi	1 x LED, hijau
---------	---------	----------------

Aksesori

Item dikirim	Klip dasar: 1, E20964
	sekup: 2 x M3 x 16
	Washer pegas: 2
	Mur: 2

Keterangan

Keterangan	tegangan pengoperasian "kelas suplai 2" menurut cULus
Jumlah paket	1 buah

Koneksi listrik

Konektor: 1 x M8; pengkodean: A



Transmitter sensor sinar tembus

OJS-00KG/FO/AS

Koneksi

