


Transmitter sensor sinar tembus

OSS-000A

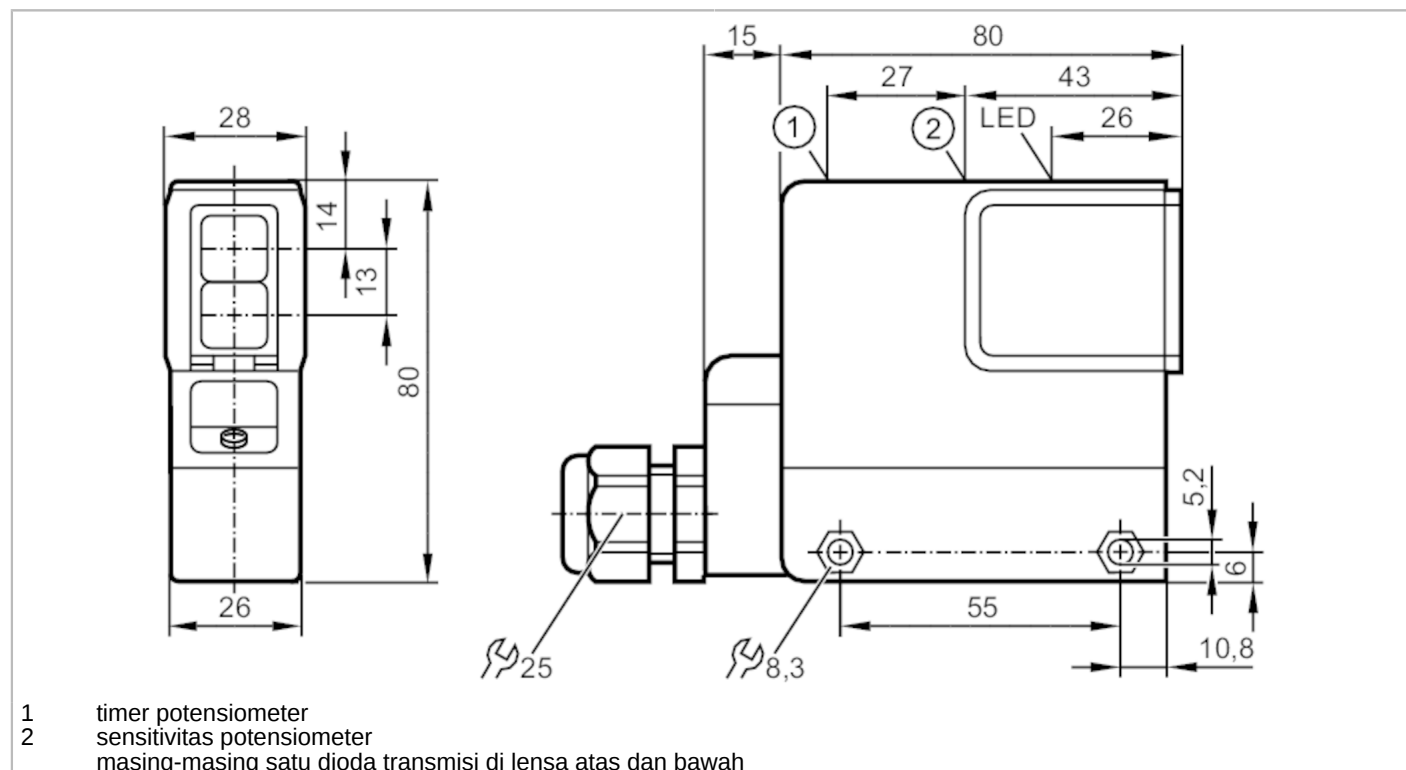

Karakteristik produk

Tipe cahaya	cahaya inframerah
Casing	persegi panjang

Aplikasi

Prinsip fungsi	Sensor sinar tembus
----------------	---------------------

Data kelistrikan

Frekuensi AC	[Hz]	47...63
Tegangan pengoperasian	[V]	20...250 AC/DC
Konsumsi arus	[mA]	18
Kelas perlindungan		II
Tipe cahaya		cahaya inframerah
Panjang gelombang	[nm]	880

Output

Frekuensi peralihan AC	[Hz]	25
Frekuensi peralihan DC	[Hz]	100
Pelindung hubung singkat		tidak
Pelindung beban berlebih		tidak

Zona pendeteksian

Transmitter/receiver		transmitter
Jarak jangkauan	[m]	< 20
Jangkauan yang dapat disesuaikan		tidak



Transmitter sensor sinar tembus

OSS-000A

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 65
Pengujian/persetujuan		
EME	EN 60947-5-2	
	EN 55011	kelas B
MTTF	[ANN]	1036
Data teknis		
Berat	[g]	265
Casing		persegi panjang
Dimensi	[mm]	80 x 28 x 95
Material		PPO dimodifikasi
Material lensa		kaca
Penyelarasan lensa		lensa samping
Elemen display/pengoperasian		
Display	operasi	1 x LED, kuning
Aksesori		
Item dikirim	Braket siku: 1, E20210	
	obeng	
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
terminal: ...1.5 mm²; Konektor kabel: M20 X 1.5		
Koneksi		

