


Transmitter sensor sinar tembus

OSS-00KG

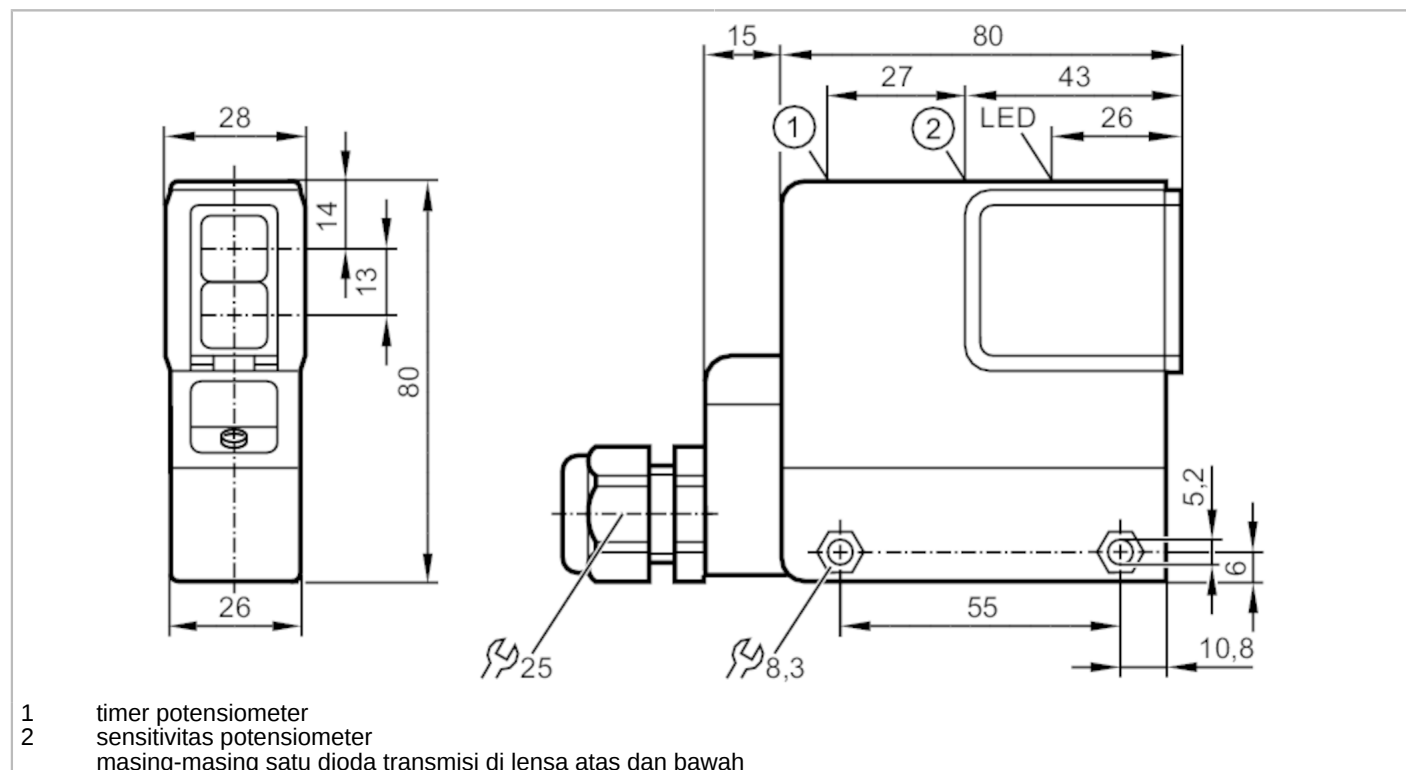

Karakteristik produk

Tipe cahaya	cahaya inframerah
Casing	persegi panjang

Aplikasi

Prinsip fungsi	Sensor sinar tembus
----------------	---------------------

Data kelistrikan

Tegangan pengoperasian [V]	10...55 DC
Konsumsi arus [mA]	20; ((24 V))
Kelas perlindungan	II
Pelindung polaritas terbalik	ya
Tipe cahaya	cahaya inframerah
Panjang gelombang [nm]	880

Zona pendeteksian

Transmitter/receiver	transmitter
Jarak jangkauan [m]	< 20
Jangkauan yang dapat disesuaikan	ya

Kondisi pengoperasian

Suhu sekitar [°C]	-25...80
Perlindungan	IP 65

Pengujian/persetujuan

EME	EN 60947-5-2
MTTF [ANN]	1801



Transmitter sensor sinar tembus

OSS-00KG

Data teknis		
Berat	[g]	264
Casing		persegi panjang
Dimensi	[mm]	80 x 28 x 95
Material		PPO dimodifikasi
Material lensa		kaca
Penyelarasan lensa		lensa samping
Elemen display/pengoperasian		
Display	operasi	1 x LED, kuning
Aksesori		
Item dikirim	Braket siku: 1, E20210	
	obeng	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
terminal: ...1.5 mm ² ; Konektor kabel: M20 X 1.5		
Koneksi		

