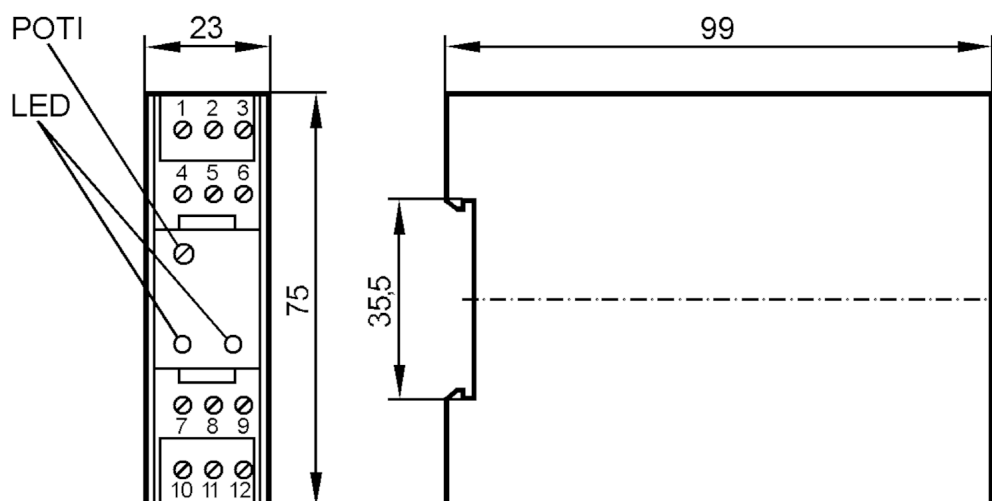


Produk tidak tersedia - entri arsip

**Data kelistrikan**

Tegangan pengoperasian	[V]	10...55 DC
Konsumsi arus	[mA]	40; (24 V)

Output

Jumlah total output	1
Desain kelistrikan	PNP/NPN
Fungsi output	mode light-on/dark-on; (dapat ditentukan parameternya)
Frekuensi peralihan DC [Hz]	100

Kondisi pengoperasian

Suhu sekitar	[°C]	0...70
Perlindungan		IP 40
Terminal peringkat perlindungan		IP 20

Data teknis

Berat	[g]	135.5
Casing		casing untuk pemasangan rel DIN
Material		PBT

Elemen display/pengoperasian

Display	status peralihan	1 x LED, merah
	alat bantuan pengaturan	1 x LED, kuning

Keterangan


Jumlah paket	1 buah
--------------	--------



Koneksi listrik

terminal: 12 x ...2.5 mm²

Koneksi

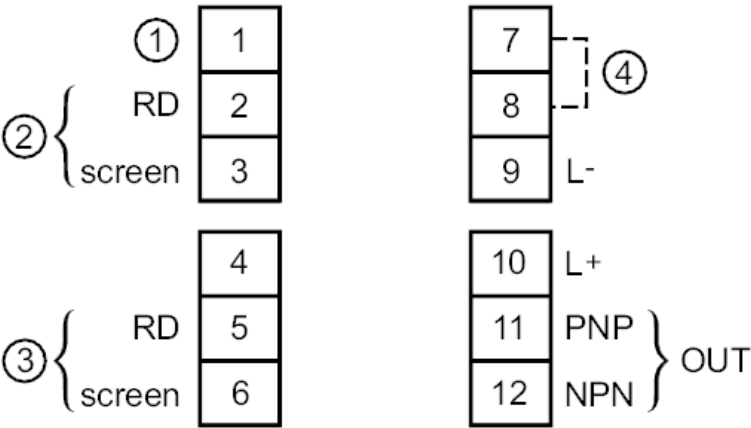

- 1 sinyal pemblokiran
- 2 transmitter
- 3 receiver
- 4 Fungsi output
- OUT output transistor