

Safety light curtain

OYA0460-30-4-12-P-1

Untuk soket 8 terminal, warna core tidak distandarisasi.
Perhatikan perkabelan sensor dan soket (lihat lembar data).



- | | |
|---|-----------------------------------|
| T | transmitter |
| R | receiver |
| 1 | LED tiga warna merah/hijau/oranye |
| 2 | LED kuning |
| 3 | LED 2 warna merah/hijau |



Karakteristik produk

Tipe cahaya	cahaya inframerah
Desain kelistrikan	PNP
Perlindungan	IP 65; IP 67

Aplikasi

Fungsi pelindung	pencegah akses untuk pelindung tangan
------------------	---------------------------------------



Safety light curtain

OYA0460-30-4-12-P-1

Data kelistrikan		
Toleransi tegangan pengoperasian	[%]	20
Tegangan pengoperasian	[V]	24 DC
Kelas perlindungan		III
Pelindung polaritas terbalik		ya
Waktu penundaan pengaktifan	[s]	< 2
Tipe cahaya		cahaya inframerah
Panjang gelombang	[nm]	950
Receiver		
Konsumsi arus	[mA]	83
Transmitter		
Konsumsi arus	[mA]	42
Output		
Desain kelistrikan		PNP
Jumlah output OSSD		2
Beban arus maksimal per output OSSD	[mA]	400; (24 V)
Pelindung hubung singkat		ya
Zona pendeteksian		
Tinggi area yang dilindungi	[mm]	460
Resolusi (kapasitas deteksi d)	[mm]	30
Lebar area perlindungan (intensitas cahaya rendah)	[m]	0...4
Lebar area perlindungan (intensitas cahaya tinggi)	[m]	3...12
Waktu respons		
Waktu respons	[ms]	7.5
Kondisi pengoperasian		
Aplikasi		kelas C sesuai aplikasi tahan cuaca berdasarkan EN 60654-1
Suhu sekitar	[°C]	-10...55
Suhu penyimpanan	[°C]	-20...70
Kelembapan udara relatif maks.	[%]	95
Perlindungan		IP 65; IP 67
Pengujian/persetujuan		
EME	IEC 61496-1	
Tahan guncangan	IEC 61496-1	
Ketahanan terhadap getaran	IEC 61496-1	
Klasifikasi keamanan		
Tipe ESPE (IEC 61496-1)		4
Memenuhi persyaratan		ISO 13849-1: 2015 kategori 4, PL e
		IEC 61508 SIL 3
		IEC 62061 SIL 3

Safety light curtain

OYA0460-30-4-12-P-1

Waktu misi TM	[h]	175200
PFH	[1/h]	9,5E-09


Data teknis		
Berat	[g]	2000
Dimensi	[mm]	513 x 28 x 30
Material		casing: aluminium; lensa depan: PC
Panjang L	[mm]	513

Elemen display/pengoperasian		
Display	transmitter	1 x LED
	receiver	2 x LED


Aksesori	
Item dikirim	braket pemasangan: 4
	mur slot: 4
	Mur

Keterangan	
Jumlah paket	1 buah

Koneksi listrik - receiver

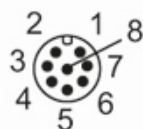Konektor: 1 x M12; pengkodean: A; Panjang kabel maksimal: 100 m; untuk penampang kawat 0.34 mm²

Koneksi

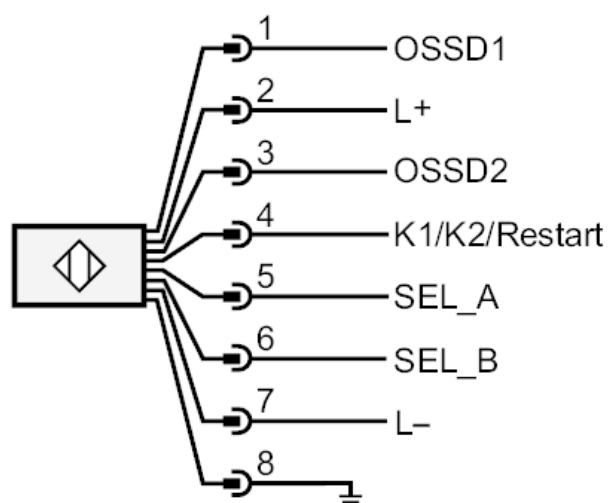

Safety light curtain

OYA0460-30-4-12-P-1

Koneksi listrik - transmitter

Konektor: 1 x M12; pengkodean: A



Koneksi

