


Safety light curtain

OYA0910-30-2-12-P-1

Untuk soket 8 terminal, warna core tidak distandarisasi.
Perhatikan perkabelan sensor dan soket (lihat lembar data).

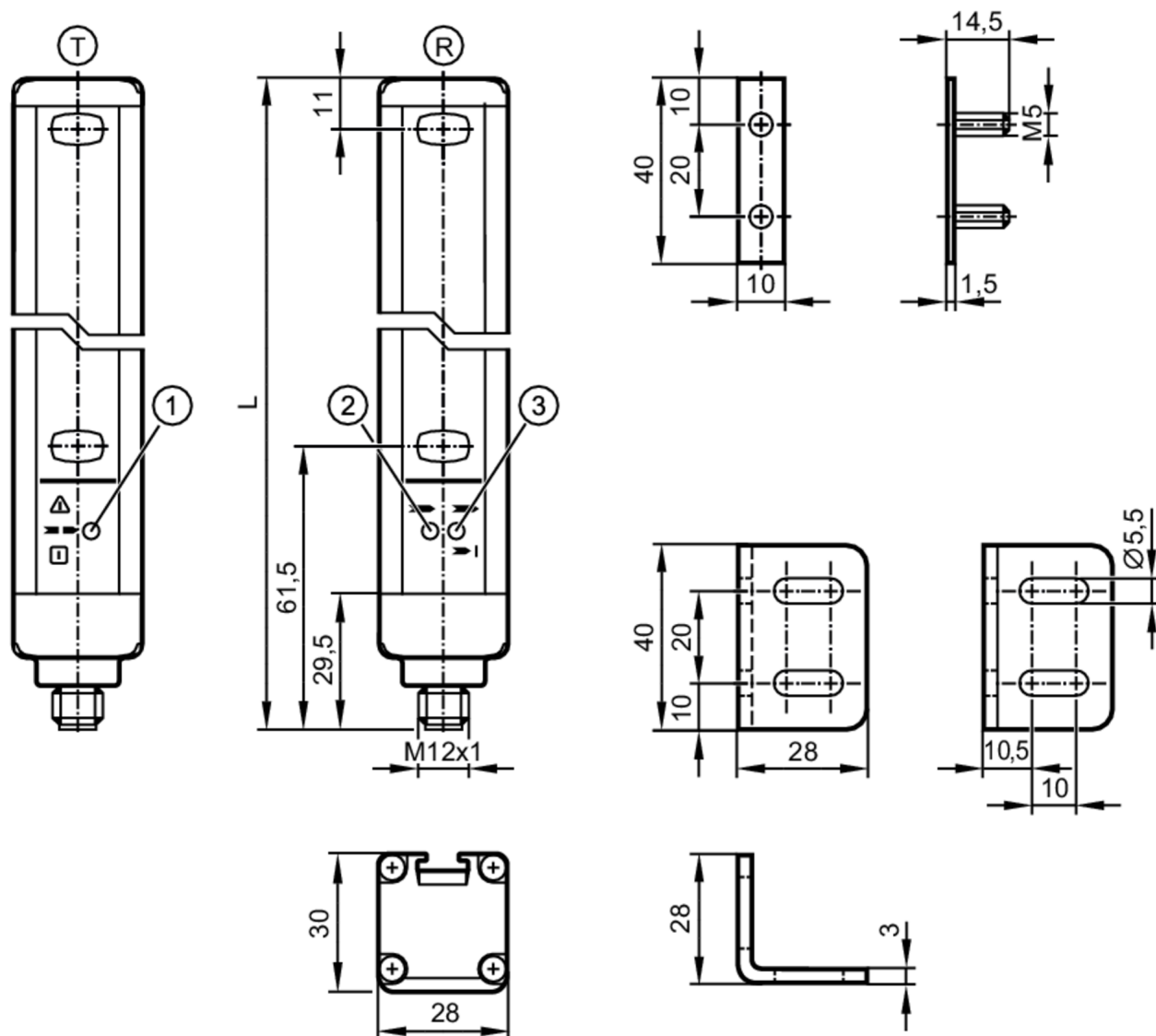

- T transmitter
R receiver
1 LED tiga warna merah/hijau/oranye
2 LED kuning
3 LED 2 warna merah/hijau



Karakteristik produk

Tipe cahaya	cahaya inframerah
Desain kelistrikan	PNP
Perlindungan	IP 65; IP 67

Aplikasi

Fungsi pelindung	pencegah akses untuk pelindung tangan
------------------	---------------------------------------



Safety light curtain

OYA0910-30-2-12-P-1

Data kelistrikan		
Toleransi tegangan pengoperasian	[%]	20
Tegangan pengoperasian	[V]	24 DC
Kelas perlindungan		III
Pelindung polaritas terbalik		ya
Waktu penundaan pengaktifan	[s]	< 2
Tipe cahaya		cahaya inframerah
Panjang gelombang	[nm]	950
Receiver		
Konsumsi arus	[mA]	83
Transmitter		
Konsumsi arus	[mA]	42
Output		
Desain kelistrikan		PNP
Jumlah output OSSD		2
Beban arus maksimal per output OSSD	[mA]	400; (24 V)
Pelindung hubung singkat		ya
Zona pendeteksian		
Tinggi area yang dilindungi	[mm]	910
Resolusi (kapasitas deteksi d)	[mm]	30
Lebar area perlindungan (intensitas cahaya rendah)	[m]	0...4
Lebar area perlindungan (intensitas cahaya tinggi)	[m]	3...12
Waktu respons		
Waktu respons	[ms]	12.5
Kondisi pengoperasian		
Aplikasi		kelas C sesuai aplikasi tahan cuaca berdasarkan EN 60654-1
Suhu sekitar	[°C]	-10...55
Suhu penyimpanan	[°C]	-20...70
Kelembapan udara relatif maks.	[%]	95
Perlindungan		IP 65; IP 67
Pengujian/persetujuan		
EME	IEC 61496-1	
Tahan guncangan	IEC 61496-1	
Ketahanan terhadap getaran	IEC 61496-1	
Klasifikasi keamanan		
Tipe ESPE (IEC 61496-1)		2
Memenuhi persyaratan		ISO 13849-1: 2015 kategori 2, PL c
		IEC 62061 SIL 1
Waktu misi TM	[h]	175200

Safety light curtain

OYA0910-30-2-12-P-1

PFH	[1/h]	5,1E-08
-----	-------	---------

Data teknis

Berat	[g]	3395
Dimensi	[mm]	963 x 28 x 30
Material	casing: aluminium; lensa depan: PC	
Panjang L	[mm]	963

Elemen display/pengoperasian

Display	transmitter	1 x LED
	receiver	2 x LED


Aksesori

Item dikirim	braket pemasangan: 4	
	mur slot: 4	
	Mur	


Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - receiver

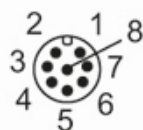Konektor: 1 x M12; pengkodean: A; Panjang kabel maksimal: 100 m; untuk penampang kawat 0.34 mm²

Koneksi

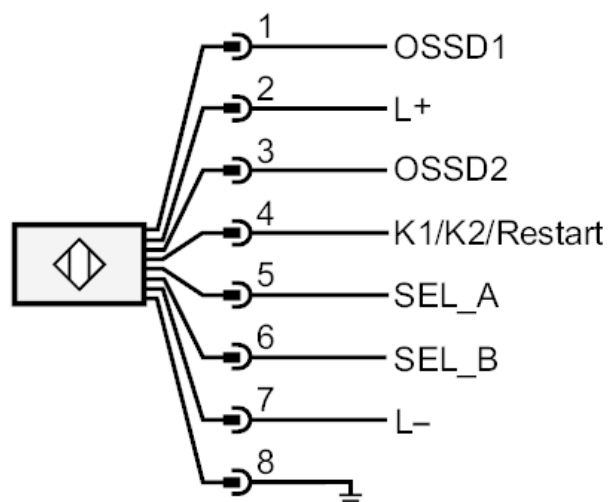


Safety light curtain

OYA0910-30-2-12-P-1

Koneksi listrik - transmitter

Konektor: 1 x M12; pengkodean: A

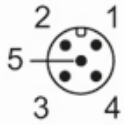

Koneksi

