


Safety light curtain

OYA0910-20-4-18-P-1-B

Untuk soket 8 terminal, warna core tidak distandarisasi.
Perhatikan perkabelan sensor dan soket (lihat lembar data).

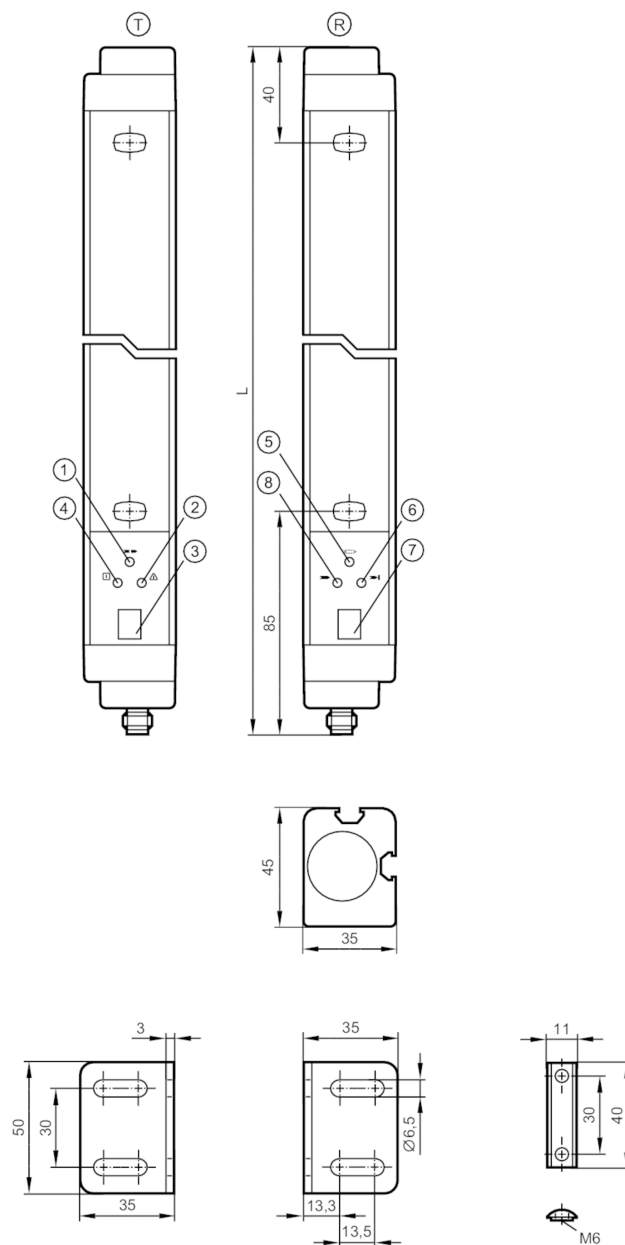

- T transmitter
- R receiver
- 1 LED kuning
- 2 LED merah
- 3 display LED 7 segmen
- 4 LED hijau
- 5 LED kuning
- 6 LED merah
- 7 display LCD 7 segmen
- 8 LED hijau



Karakteristik produk

Tipe cahaya

cahaya inframerah



Safety light curtain


OYA0910-20-4-18-P-1-B

Desain kelistrikan	PNP
Perlindungan	IP 65
Aplikasi	
Fungsi pelindung	pencegah akses untuk pelindung tangan
Data kelistrikan	
Toleransi tegangan pengoperasian [%]	20
Tegangan pengoperasian [V]	24 DC
Kelas perlindungan	III
Pelindung polaritas terbalik	ya
Waktu penundaan pengaktifan [s]	< 18
Tipe cahaya	cahaya inframerah
Panjang gelombang [nm]	950
Receiver	
Konsumsi arus [mA]	125
Transmitter	
Konsumsi arus [mA]	83
Output	
Desain kelistrikan	PNP
Jumlah output OSSD	2
Beban arus maksimal per output OSSD [mA]	500; (24 V)
Pelindung hubung singkat	ya
Zona pendeteksian	
Tinggi area yang dilindungi [mm]	910
Resolusi (kapasitas deteksi d) [mm]	20
Lebar area perlindungan (intensitas cahaya rendah) [m]	0...6
Lebar area perlindungan (intensitas cahaya tinggi) [m]	3...18
Pengosongan mengambang	ya
Waktu respons	
Waktu respons [ms]	15.5
Kondisi pengoperasian	
Aplikasi	kelas C sesuai aplikasi tahan cuaca berdasarkan EN 60654-1
Suhu sekitar [°C]	0...55
Kelembapan udara relatif maks. [%]	95
Perlindungan	IP 65
Pengujian/persetujuan	
EME	IEC 61496-1
Tahan guncangan	IEC 61496-1
Ketahanan terhadap getaran	IEC 61496-1



Safety light curtain


OYA0910-20-4-18-P-1-B

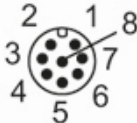Klasifikasi keamanan		
Tipe ESPE (IEC 61496-1)	4	
Memenuhi persyaratan	ISO 13849-1: 2015 kategori 4, PL e	
	IEC 61508 SIL 3	
	IEC 62061 SIL 3	
Waktu misi TM	[h]	175200
PFH	[1/h]	1,8E-08
Data teknis		
Berat	[g]	5030
Dimensi	[mm]	1011 x 35 x 45
Material	casing: aluminium; lensa depan: PC	
Panjang L	[mm]	1011
Elemen display/pengoperasian		
Display	transmitter	3 x LED
	transmitter	display LCD 7 segmen
	receiver	3 x LED
	receiver	display LCD 7 segmen
Aksesori		
Item dikirim	braket pemasangan: 4	
	mur slot: 4	
	sekrup	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik - receiver		
Konektor: 1 x M12; pengkodean: A; Panjang kabel maksimal: 100 m; untuk penampang kawat 0.34 mm ²		
		

Safety light curtain


OYA0910-20-4-18-P-1-B

Koneksi

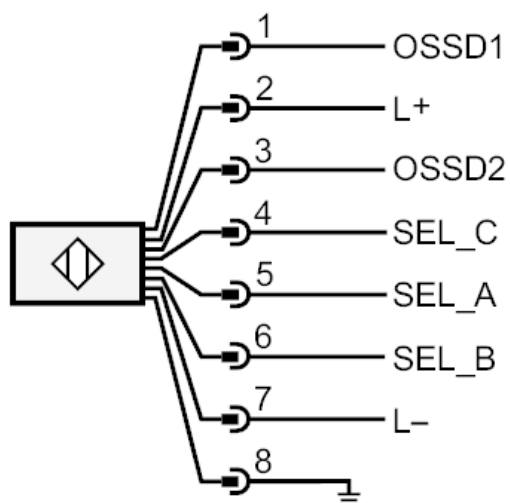

Koneksi listrik - transmitter

Konektor: 1 x M12; pengkodean: A

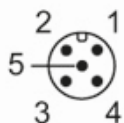

Koneksi

