


Sensor aliran untuk koneksi ke satu unit evaluasi

SFR12ADB/US-100

Produk tidak tersedia - entri arsip

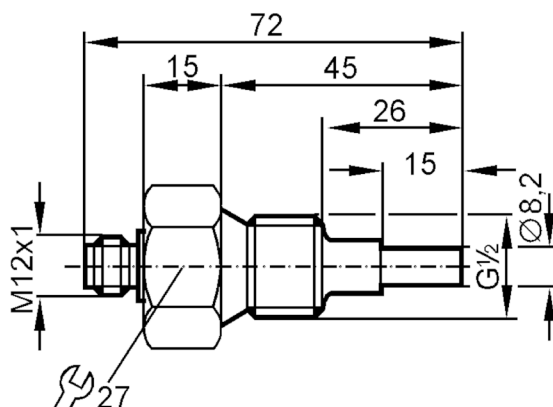

Karakteristik produk

Koneksi proses	G 1/2
----------------	-------

Aplikasi

Suhu media	[°C]	-25...80
Peringkat tekanan	[bar]	300

Rentang pengukuran/pengaturan

Cairan

Rentang pengaturan	[cm/s]	3...300
Sensitivitas terbesar	[cm/s]	3...60

Gas

Rentang pengaturan	[cm/s]	200...2000
Sensitivitas terbesar	[cm/s]	200...800

Kondisi pengoperasian

Perlindungan	IP 67
--------------	-------

Data teknis

Casing	tipe berulir
Dimensi [mm]	27 x 27 x 72
Material	baja tahan karat (1.4571 / 316Ti)
Material yang kontak dengan media	baja tahan karat (1.4571 / 316Ti)
Koneksi proses	G 1/2




Sensor aliran untuk koneksi ke satu unit evaluasi


SFR12ADB/US-100

Koneksi listrik

Konektor: 1 x M12; pengkodean: A; Panjang kabel maksimal: 100 (5 x 0.5mm²) m

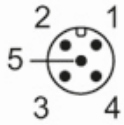

Koneksi

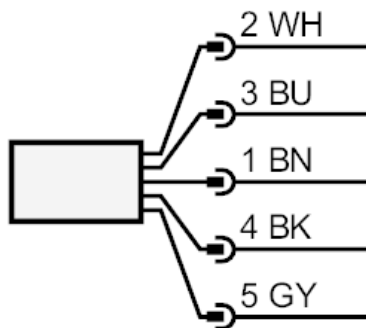

BN = coklat
 BU = biru
 BK = hitam
 WH = putih
 GY = abu-abu