


Pemantau aliran udara

SLG23XEE40KG/2M

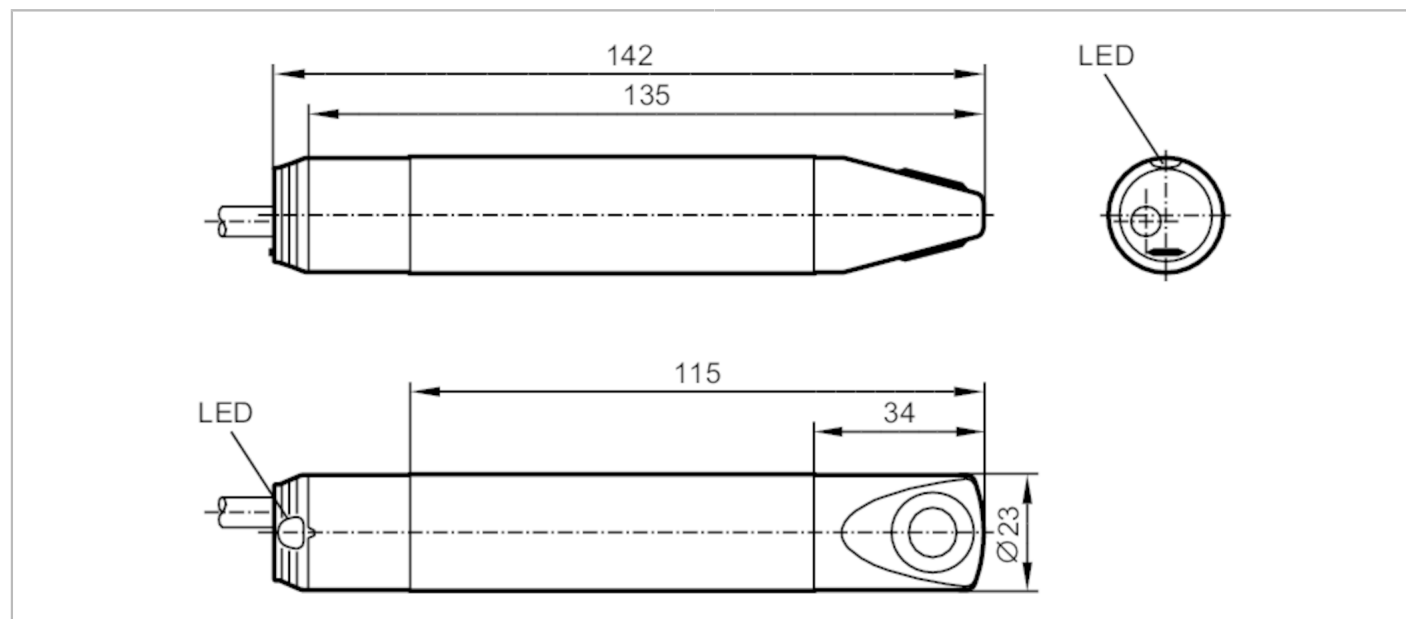

Karakteristik produk

Jumlah input dan output	Jumlah output analog: 1
Koneksi proses	Ø 23 mm

Aplikasi

Suhu media	[°C]	20...40
Peringkat tekanan	[bar]	1

Data kelistrikan

Toleransi tegangan pengoperasian	[%]	-10...10
Tegangan pengoperasian	[V]	24 DC
Konsumsi arus	[mA]	< 35
Resistensi isolasi min.	[MΩ]	100; (500 V DC)
Waktu penundaan pengaktifan	[s]	90

Input/output

Jumlah input dan output	Jumlah output analog: 1
-------------------------	-------------------------

Output

Jumlah total output	1
Sinyal output	sinyal analog
Jumlah output analog	1
Output tegangan analog [V]	0...10

Rentang pengukuran/pengaturan

Rentang aliran	[cm/s]	200...3000
Catatan tentang rentang aliran		= 1...10 V

Akurasi/deviasi


Gradien suhu	[K/min]	1
--------------	---------	---



Pemantau aliran udara

SLG23XEE40KG/2M

Kondisi pengoperasian		
Suhu sekitar	[°C]	-10...40
Suhu penyimpanan	[°C]	-25...85
Perlindungan		IP 65
Pengujian/persetujuan		
MTTF	[ANN]	727
Data teknis		
Berat	[g]	195
Dimensi	[mm]	Ø 23 / L = 142
Material		casing: PBT; permukaan sensor: titanium
Material yang kontak dengan media		PBT; titanium
Koneksi proses		Ø 23 mm
Elemen display/pengoperasian		
Display	operasi	LED, hijau
Aksesori		
Item dikirim		Klem pemasangan: 1, E40048
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 2 m, PUR; 4 x 0.5 mm², PVC		
Koneksi		

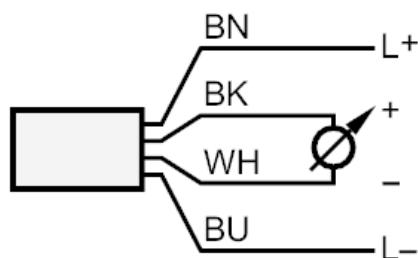

Warna core :

BK = hitam

BN = coklat

BU = biru

WH = putih