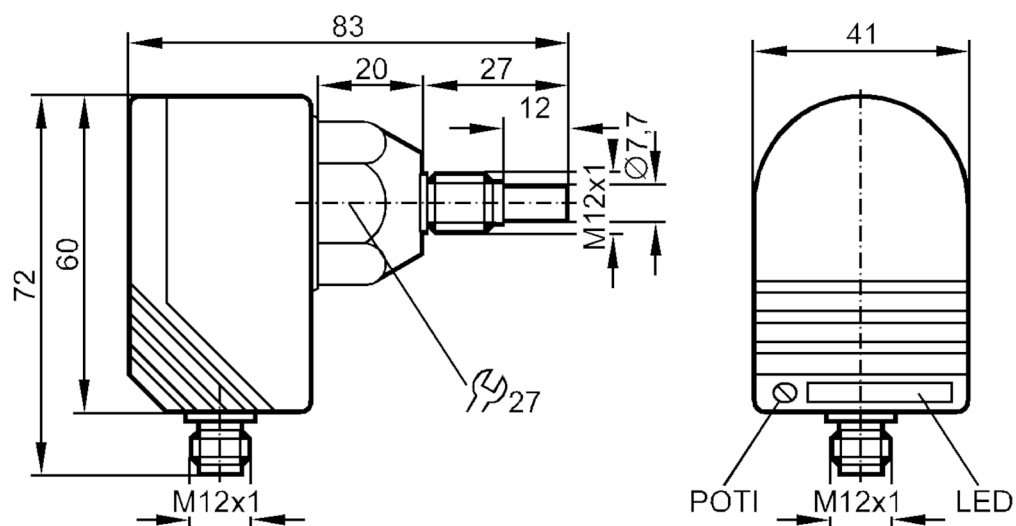


Produk tidak tersedia - entri arsip

**Karakteristik produk**

|                |         |
|----------------|---------|
| Koneksi proses | M12 x 1 |
|----------------|---------|

**Aplikasi**

|                         |          |
|-------------------------|----------|
| Media                   | Cairan   |
| Suhu media [°C]         | -25...80 |
| Peringkat tekanan [bar] | 30       |

**Data kelistrikan**

|                                 |                |
|---------------------------------|----------------|
| Tegangan pengoperasian [V]      | 26.5...31.6 DC |
| Konsumsi arus [mA]              | < 45           |
| Kelas perlindungan              | II             |
| Pelindung polaritas terbalik    | ya             |
| Waktu penundaan pengaktifan [s] | < 20           |

**Output**

|                          |      |
|--------------------------|------|
| Desain kelistrikan       | AS-i |
| Pelindung beban berlebih | ya   |

**Rentang pengukuran/pengaturan**

|                              |         |
|------------------------------|---------|
| Rentang pengaturan [cm/s]    | 3...300 |
| Sensitivitas terbesar [cm/s] | 3...60  |

**Akurasi/deviasi**

|                      |    |
|----------------------|----|
| Gradien suhu [K/min] | 15 |
|----------------------|----|



## Pemantau aliran

SCM12ABAASI /US-100

| Waktu respons                                                                       |        |                               |
|-------------------------------------------------------------------------------------|--------|-------------------------------|
| Waktu respons                                                                       | [s]    | 1...10                        |
| Software/pemrograman                                                                |        |                               |
| Penyesuaian titik peralihan                                                         |        | potensiometer                 |
| Kondisi pengoperasian                                                               |        |                               |
| Suhu sekitar                                                                        | [°C]   | -20...80                      |
| Perlindungan                                                                        |        | IP 67                         |
| Klasifikasi AS-i                                                                    |        |                               |
| Konfigurasi I/O AS-i                                                                | [hex]  | 1                             |
| Kode ID AS-i                                                                        | [hex]  | 1                             |
| Data teknis                                                                         |        |                               |
| Dimensi                                                                             | [mm]   | M12 x 1                       |
| Penamaan ulir                                                                       |        | M12 x 1                       |
| Material                                                                            |        | PBT-GF20                      |
| Material yang kontak dengan media                                                   |        | baja tahan karat (1.4305/303) |
| Koneksi proses                                                                      |        | M12 x 1                       |
| Elemen display/pengoperasian                                                        |        |                               |
| Display                                                                             | fungsi | 11 x LED                      |
| Aksesori                                                                            |        |                               |
| Item dikirim                                                                        |        | segel: 2 x AMF 30<br>obeng    |
| Keterangan                                                                          |        |                               |
| Jumlah paket                                                                        |        | 1 buah                        |
| Koneksi listrik                                                                     |        |                               |
| Konektor: 1 x M12; pengkodean: A                                                    |        |                               |
|  |        |                               |



## Pemantau aliran

SCM12ABAASI /US-100

### Koneksi

