




Sensor aliran untuk koneksi ke satu unit evaluasi

STR14ABBE1/10m

Produk tidak tersedia - entri arsip

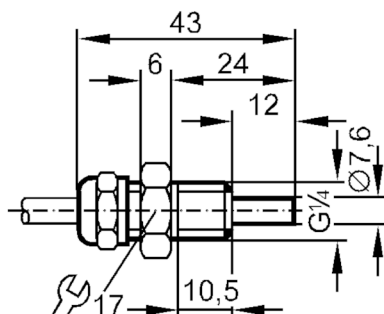

Karakteristik produk

Koneksi proses	G 1/4 ulir eksternal
----------------	----------------------

Aplikasi

Aplikasi	Eks zona 1
Suhu media [°C]	-25...80
Peringkat tekanan [bar]	30

Cairan

Aplikasi	Eks zona 1
Suhu media [°C]	-25...80

Gas

Suhu media [°C]	-25...80
-----------------	----------

Data kelistrikan

Koneksi ke monitor kontrol	VS 0100 Ex
----------------------------	------------

Rentang pengukuran/pengaturan

Cairan

Rentang pengaturan [cm/s]	3...300
Sensitivitas terbesar [cm/s]	3...60

Gas

Rentang pengaturan [cm/s]	5...1500
---------------------------	----------

Akurasi/deviasi

Gradien suhu [K/min]	15
----------------------	----

Waktu respons

Waktu respons [s]	1...10
-------------------	--------

Cairan

Waktu respons [s]	1...10
-------------------	--------

Gas

Waktu respons [s]	1...10
-------------------	--------

Kondisi pengoperasian

Perlindungan	IP 67
--------------	-------

Data teknis

Casing	tipe berulir
--------	--------------




Sensor aliran untuk koneksi ke satu unit evaluasi

STR14ABBE1/10m

Material	baja tahan karat (1.4571 / 316Ti)
Koneksi proses	G 1/4 ulir eksternal

Keterangan

Jumlah paket	1 buah
--------------	--------

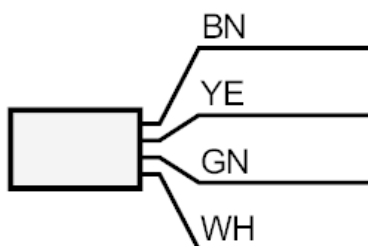Koneksi listrikKabel: 10 m, Silflex-PUR; Panjang kabel maksimal: 100 m; 4 x 0.25 mm²**Koneksi**

	Warna core :
BN =	coklat
GN =	hijau
WH =	putih
YE =	kuning