


Sensor aliran untuk koneksi ke satu unit evaluasi

STN34ABA/NPT-GEW

Produk tidak tersedia - entri arsip

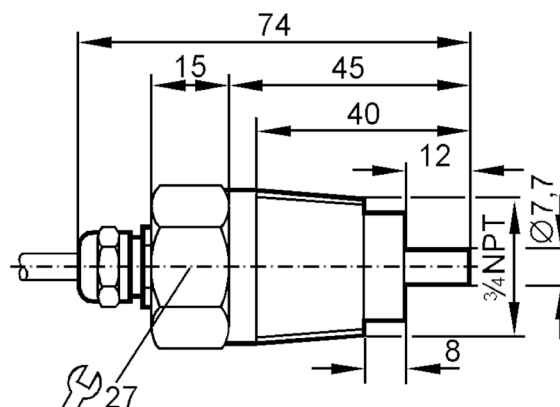

Karakteristik produk

Koneksi proses	3/4" NPT
----------------	----------

Aplikasi

Aplikasi	rentang suhu tinggi
Media	Cairan; Gas
Suhu media [°C]	-25...80
Peringkat tekanan [bar]	30

Cairan

Aplikasi	rentang suhu tinggi
Suhu media [°C]	-25...80

Gas

Suhu media [°C]	-25...80
-----------------	----------

Data kelistrikan

Koneksi ke monitor kontrol	VS 0100
----------------------------	---------

Rentang pengukuran/pengaturan

Cairan

Rentang pengaturan [cm/s]	3...300
Sensitivitas terbesar [cm/s]	3...60

Gas

Rentang pengaturan [cm/s]	5...1500
---------------------------	----------

Akurasi/deviasi

Gradien suhu [K/min]	15
----------------------	----



Sensor aliran untuk koneksi ke satu unit evaluasi

STN34ABA/NPT-GEW

Waktu respons		
Waktu respons	[s]	1...10
Cairan		
Waktu respons	[s]	1...10
Gas		
Waktu respons	[s]	1...10
Kondisi pengoperasian		
Perlindungan		IP 67
Data teknis		
Casing		tipe berulir
Material		baja tahan karat (1.4305/303)
Koneksi proses		3/4" NPT
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 2 m, Silflex-PUR; Panjang kabel maksimal: 100 m; 4 x 0.5 mm ²		
Koneksi		



Warna core :
 BK = hitam
 BN = coklat
 BU = biru
 WH = putih