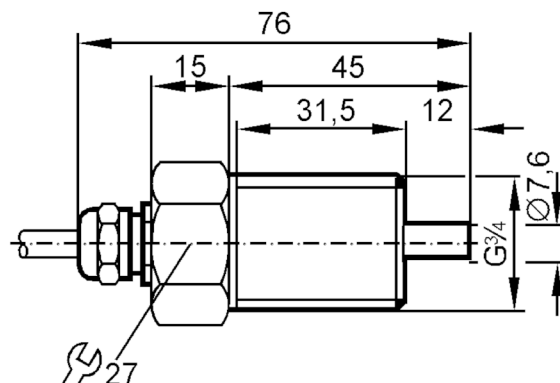


Produk tidak tersedia - entri arsip

**Karakteristik produk**

Koneksi proses	G 3/4 ulir eksternal
----------------	----------------------

Aplikasi

Aplikasi	rentang suhu tinggi
Media	Cairan; Gas
Peringkat tekanan [bar]	30

Cairan

Aplikasi	rentang suhu tinggi
Suhu media [°C]	0...120

Gas

Suhu media [°C]	0...100
-----------------	---------

Data kelistrikan

Koneksi ke monitor kontrol	VS 0100
----------------------------	---------

Rentang pengukuran/pengaturan**Cairan**

Rentang pengaturan [cm/s]	3...300
Sensitivitas terbesar [cm/s]	3...60

Gas

Rentang pengaturan [cm/s]	5...1500
---------------------------	----------

Akurasi/deviasi

Gradien suhu [K/min]	15
----------------------	----

Waktu respons

Waktu respons [s]	1...10
-------------------	--------


ST4300



Sensor aliran untuk koneksi ke satu unit evaluasi

STR34ZBB

Cairan	
Waktu respons	[s] 1...10
Gas	
Waktu respons	[s] 1...10
Kondisi pengoperasian	
Perlindungan	IP 67
Data teknis	
Casing	tipe berulir
Material	baja tahan karat (1.4571 / 316Ti)
Koneksi proses	G 3/4 ulir eksternal
Keterangan	
Jumlah paket	1 buah
Koneksi listrik	
Kabel: 2 m, silikon; Panjang kabel maksimal: 100 m; 4 x 0.5 mm ²	
Koneksi	

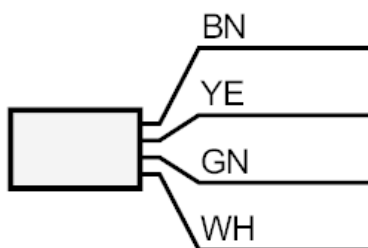

BK =
BN =
BU =
WH =

Warna core :
hitam
coklat
biru
putih