




Adaptor untuk saluran LB

CONDUIT ADPTR, DUAL M12, 3/4"

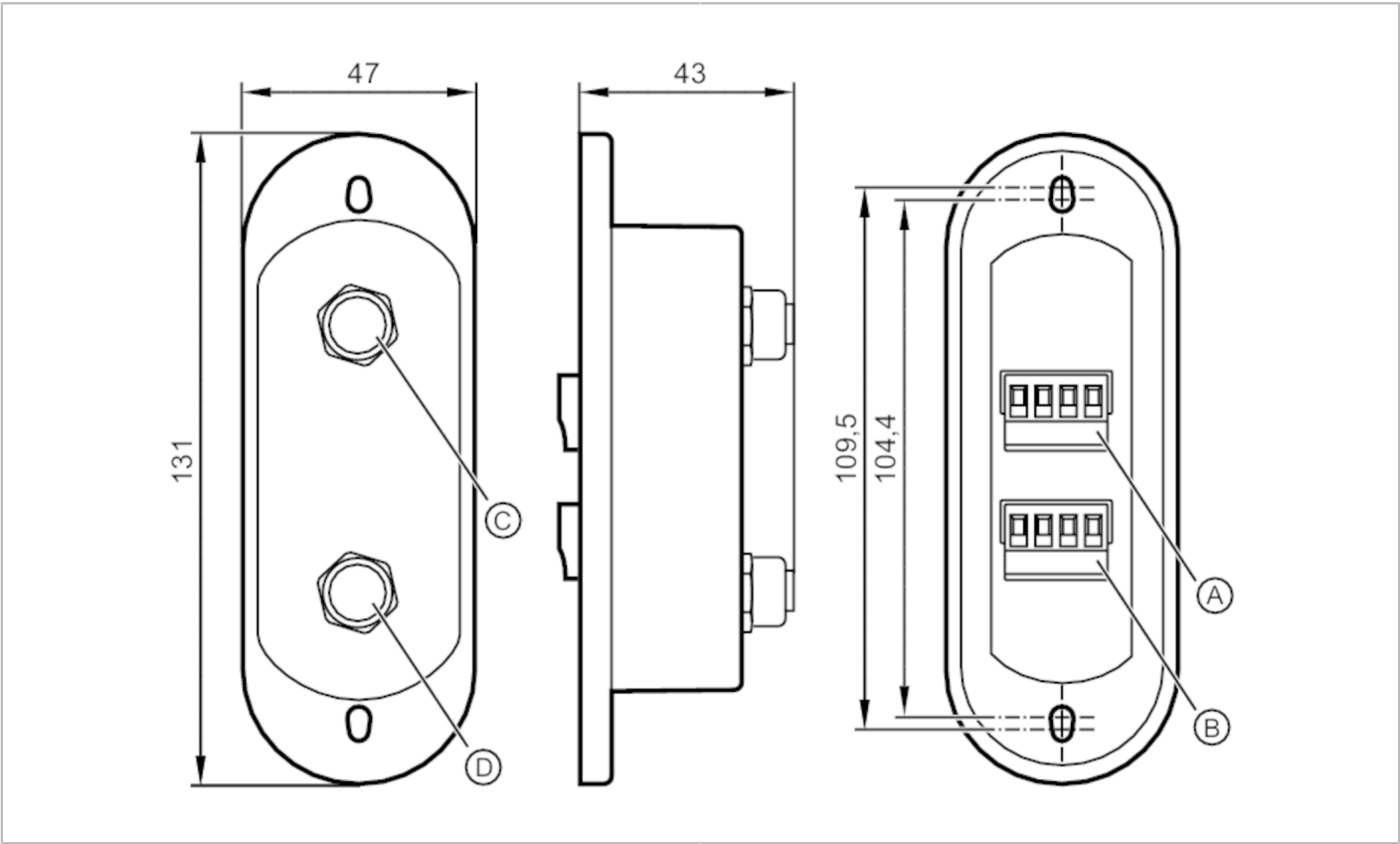

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	< 300 AC/DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...70
Data teknis		
Berat	[g]	272.155
Material		casing: PBT-GF20; Segel: NBR
Jumlah port kotak splitter		2
Keterangan		
Jumlah paket		1 buah

Adaptor untuk saluran LB

CONDUIT ADPTR, DUAL M12, 3/4"

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Kontak: dilapisi emas

**Koneksi**