

AC1392




AS-Interface EtherCAT gateway with PLC

ControllerE M4 2Mstr ECAT

discontinued article

Alternative article: AC1434 When selecting an alternative article and accessories please note that technical data may differ! –
When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2018

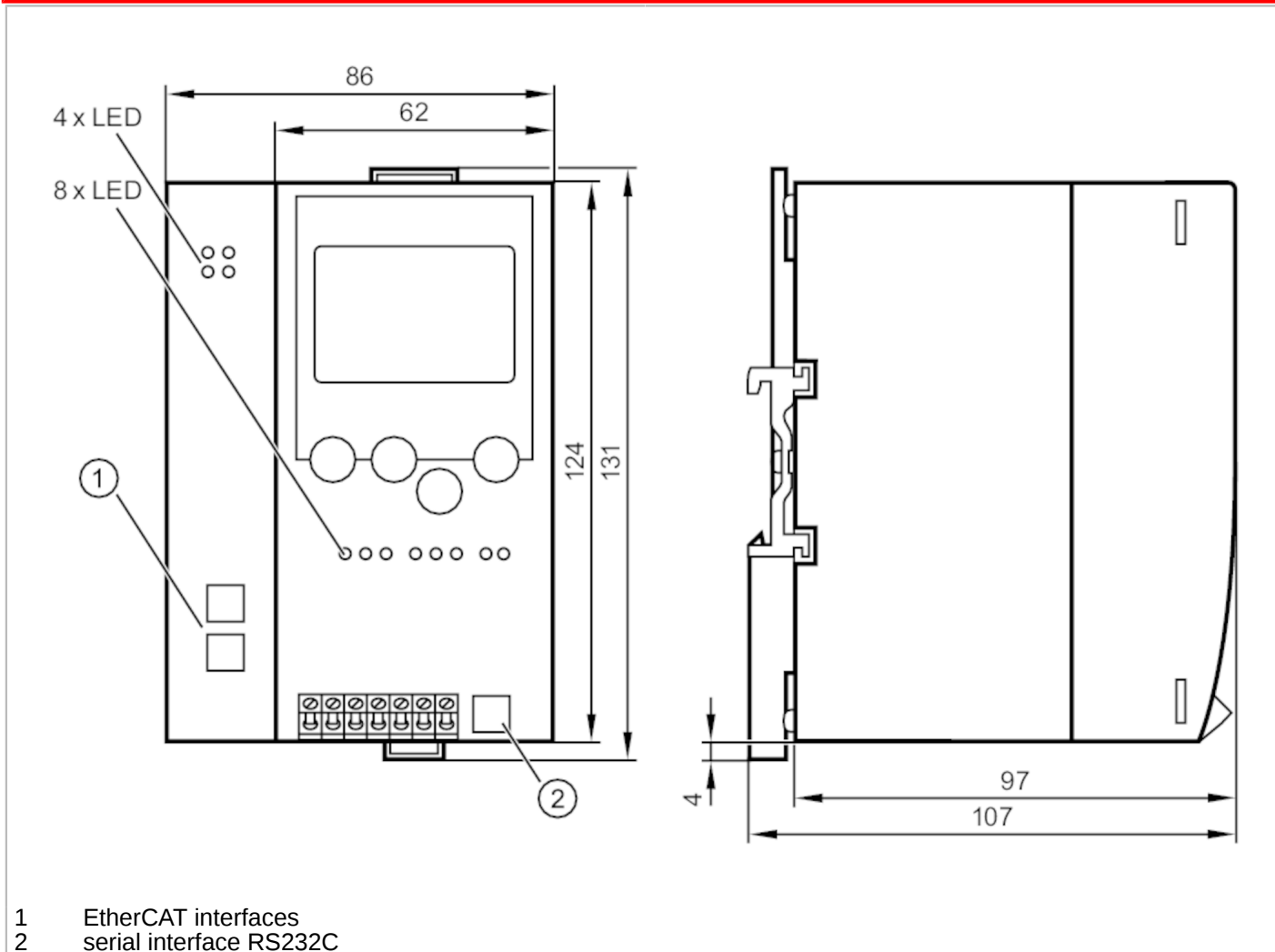

Application	
Application	decentralised controller; EtherCat gateway
Electrical data	
Operating voltage [V]	24 DC
Current consumption [mA]	< 400
Max. current consumption from AS-i [mA]	10
Max. power consumption [VA]	10
Number of AS-i masters	2
Interfaces	
Communication interface	RS232; Ethernet

AC1392



AS-Interface EtherCAT gateway with PLC

ControllerE M4 2Mstr ECAT

Ethernet - EtherCAT		
Protocol	EtherCAT	
Usage type	data transmission	
RS232		
Number of R232 interfaces	1	
Transmission rate	9600...115200 Baud	
Connector type	RJ11	
Usage type	programming	
at_schnittstelle-zusatz	electrically isolated	
Operating conditions		
Ambient temperature [°C]	0...60	
Storage temperature [°C]	-20...70	
Protection	IP 20	
AS-i classification		
AS-i version	2.1 + 3.0	
AS-i profile	M4	
AS-i certificate pending	yes	
Mechanical data		
Weight [g]	568	
Housing	housing for DIN rail mounting	
Dimensions [mm]	131 x 107 x 86	
Materials	aluminium; steel sheet galvanised	
Displays / operating elements		
Display	function	3 x LED, red
		4 x LED, green
		2 x LED, yellow
		full graphic LCD display
Remarks		
Notes	discontinued article	
Pack quantity	1 pcs.	

AC1392



AS-Interface EtherCAT gateway with PLC

ControllerE M4 2Mstr ECAT

Electrical connection

Connection



discontinued article

Alternative article: AC1434 When selecting an alternative article and accessories please note that technical data may differ! –
When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2018