


# AC2453



## AS-Interface CompactLine module

CompactM12 4 SB V4A

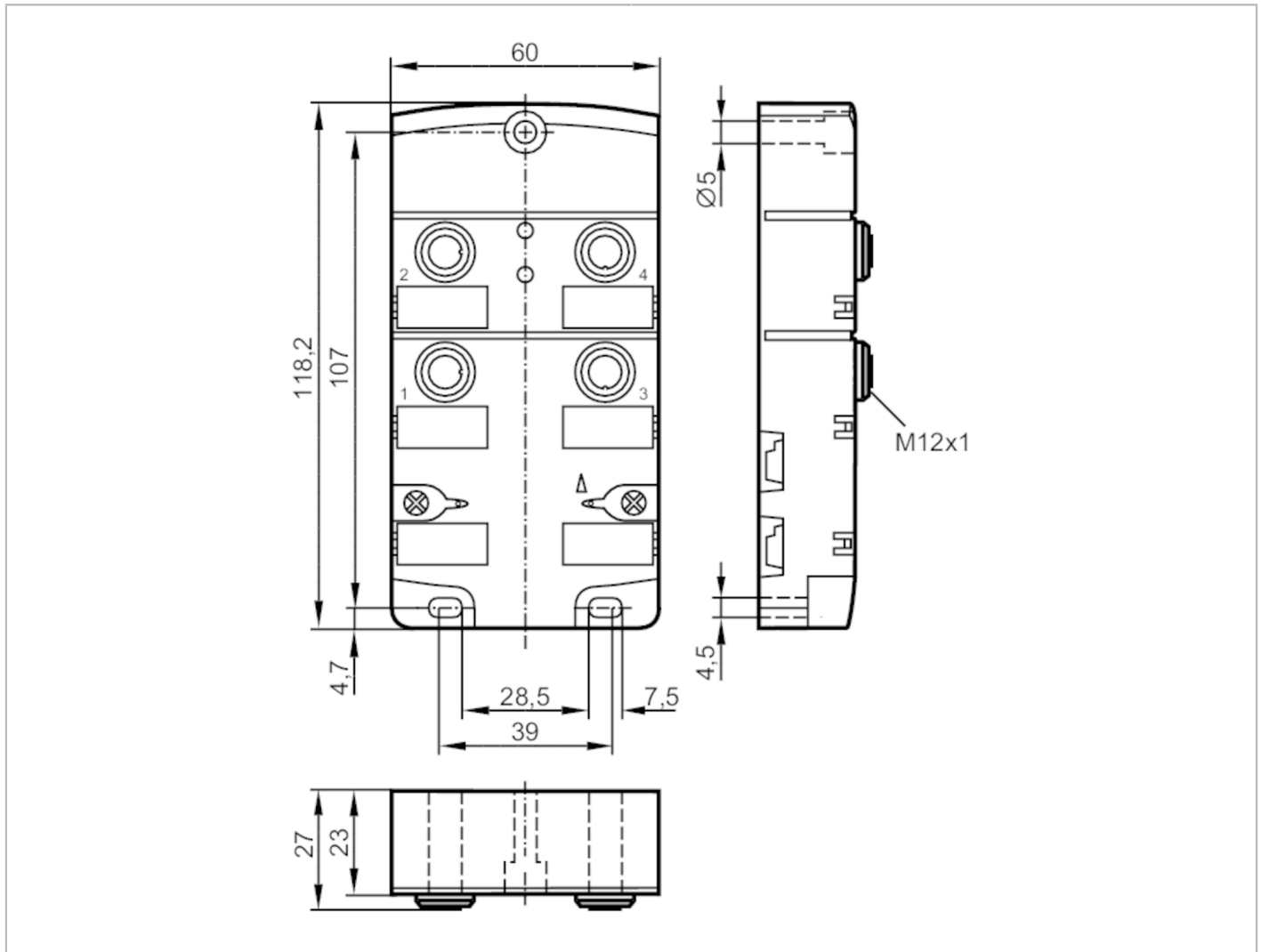

Electrical data	
Operating voltage	[V] 26.5...31.6 DC; ("supply class 2" to cULus)
Max. current load total	[A] 4
Operating conditions	
Ambient temperature	[°C] -25...80
Protection	IP 67; (when flat cables are used E7400x / E7401x)
Tests / approvals	
EMC	EN 50295
Mechanical data	
Weight	[g] 272
Type of mounting	AS-i flat cables directly connectable
Materials	PA 6.6; socket: stainless steel (1.4404 / 316L); threaded inserts in the lower part: stainless steel (1.4404 / 316L); O-ring: EPDM; piercing contacts: CuSn6 nickel-plated and tin-plated; screws stainless steel (1.4578 / 316Cu)
Accessories	
Accessories (optional)	Stainless steel sleeve, for installation in case of high mechanical stress , E70402

# AC2453



## AS-Interface CompactLine module

CompactM12 4 SB V4A

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

- |   |                       |
|---|-----------------------|
| 1 | AS-i +                |
| 2 | external voltage -    |
| 3 | AS-i -                |
| 4 | external voltage +    |
| 5 | protective earth (FE) |

Connector: M12

