

CR1201



Programmable graphic display for controlling mobile machines


R360/PDM360 NG 12"/Touch

phase-out article

Alternative articles: CR1204

When selecting an alternative article and accessories please note that technical data may differ!

Please do not use for new projects.

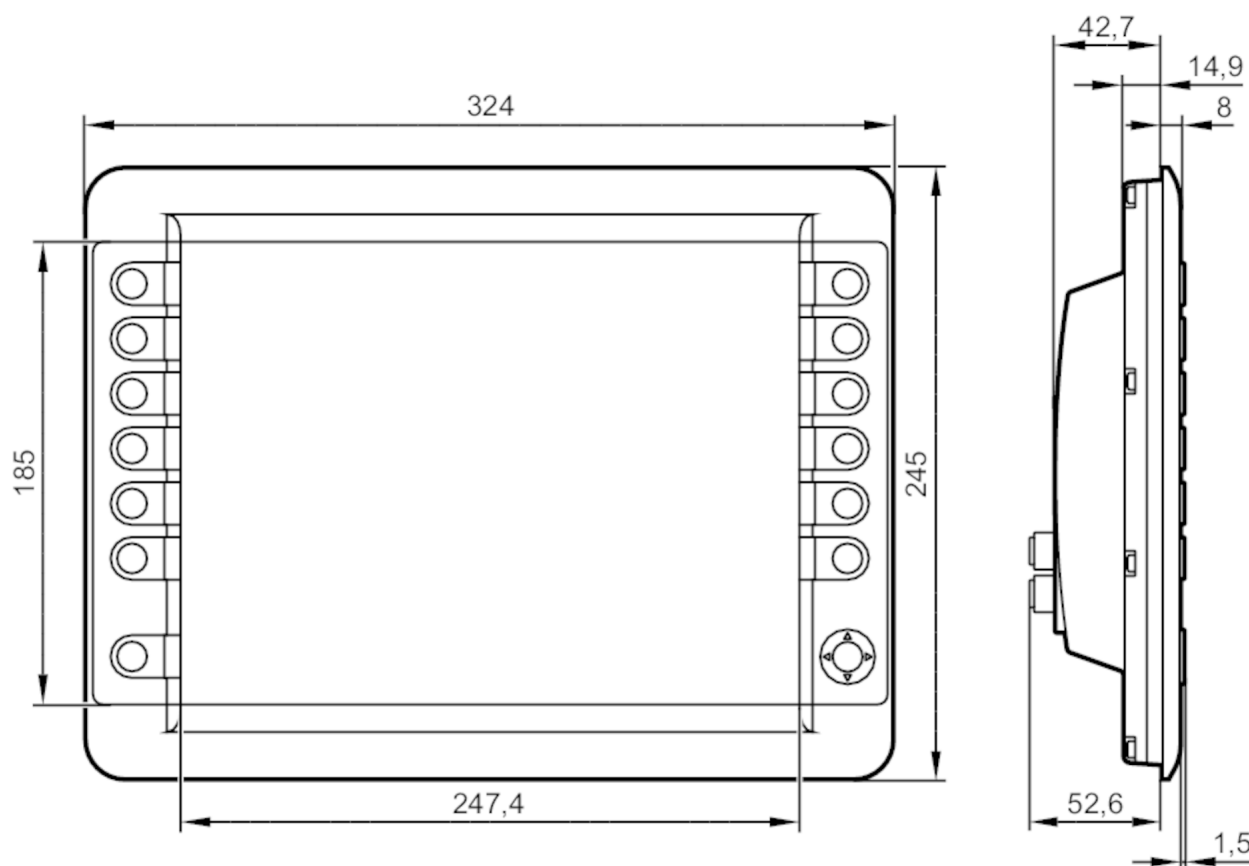

Electrical data

Operating voltage	[V]	10...32 DC
Power consumption	[W]	18

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 1; Number of analogue inputs: 1; Number of digital outputs: 1
------------------------------	---

Inputs

Number of digital inputs		1
Number of analogue inputs		1
Analogue input (current)	[mA]	0...20
Analogue input (voltage)	[V]	0...32

Outputs

Number of digital outputs	1
---------------------------	---



Programmable graphic display for controlling mobile machines

R360/PDM360 NG 12"/Touch

Software / programming		
PLC function to IEC 61131-3		yes
Interfaces		
Number of CAN interfaces		4
Number of Ethernet interfaces		1
Number of USB interfaces		2
Number of video interfaces (CVBS)		2
Mechanical data		
Weight	[g]	3574
Type of mounting		panel / surface
Dimensions	[mm]	245 x 324 x 62
Displays / operating elements		
Display		12" colour display
Operating elements	1	touch screen
	13	freely programmable backlit function keys
	1	navigation key with pushbutton
Display resolution		1024 x 768
Display type		colour display
Display size		12"
Display background illumination		LED
Data memories		
Real-time clock		yes
Remarks		
Notes		Please do not use for new projects.
Pack quantity		1 pcs.
Electrical connection		
Connector: 1 x M12		