


E10420



Connecting cable with socket

ADOGH040MSS0015G04

Article no longer available - archive entry

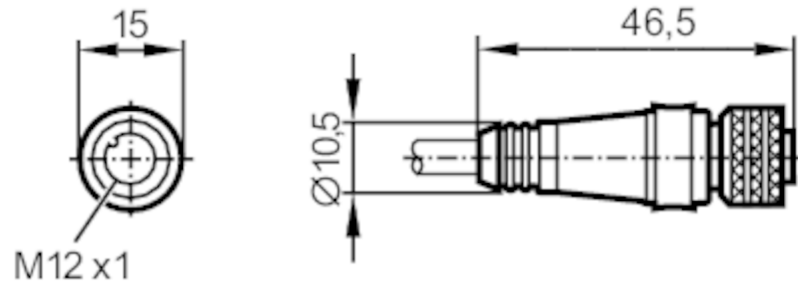

Application

Special feature Screened cable

Electrical data

Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...70
Protection	IP 67

Mechanical data

Weight [g]	578.8
Dimensions [mm]	15 x 15 x 46.5
Materials	TPU
Material nut	brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 15 m, PVC, black, Ø 5 mm, shielded; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket


Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm; Shielded connection cable: screen not connected

E10420




Connecting cable with socket

ADOGH040MSS0015G04

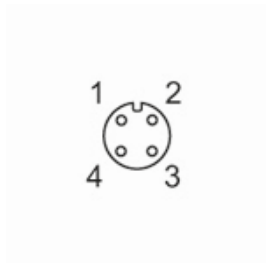

Connection

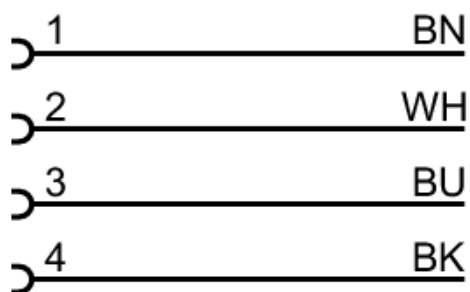

Core colours :

BN = brown
BK = black
BU = blue
WH = white

Article no longer available - archive entry