


Jumper cable with valve plug

VVSAC040MSS0001B03STGH040MSS

Article no longer available - archive entry

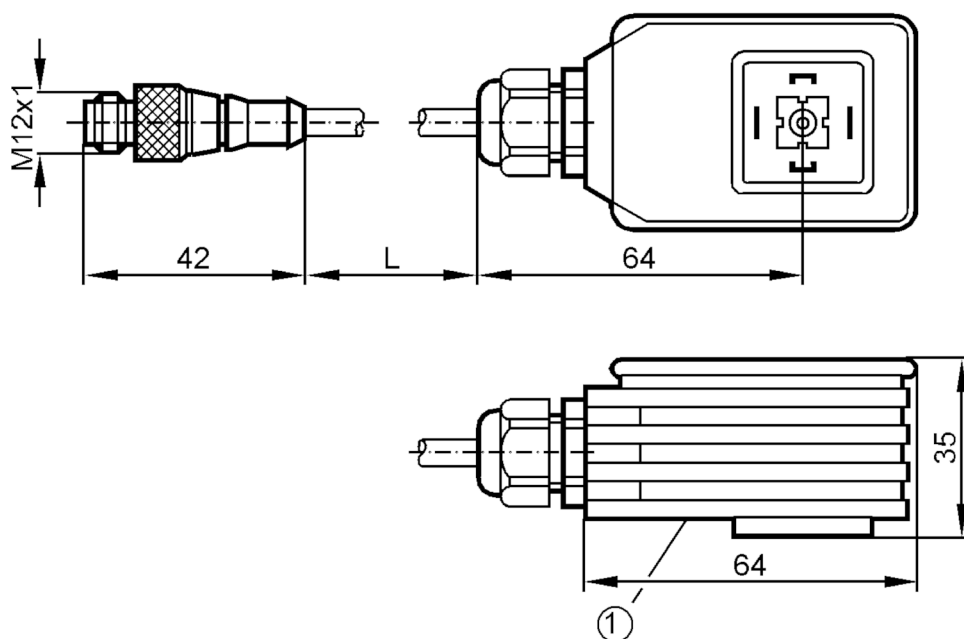

1 grey

Application

Design

with amplifier

Electrical data

Operating voltage

[V]

12...40 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 65

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10673




Jumper cable with valve plug

VVSAC040MSS0001B03STGH040MSS

Electrical connection

Cable: 1 m, PUR; 3 x 0.5 mm²

Connection

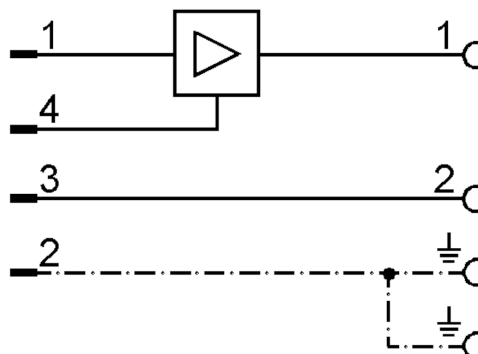

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

