


E10745



Connecting cable with socket

ADOAH040VAS0020E04

Article no longer available - archive entry

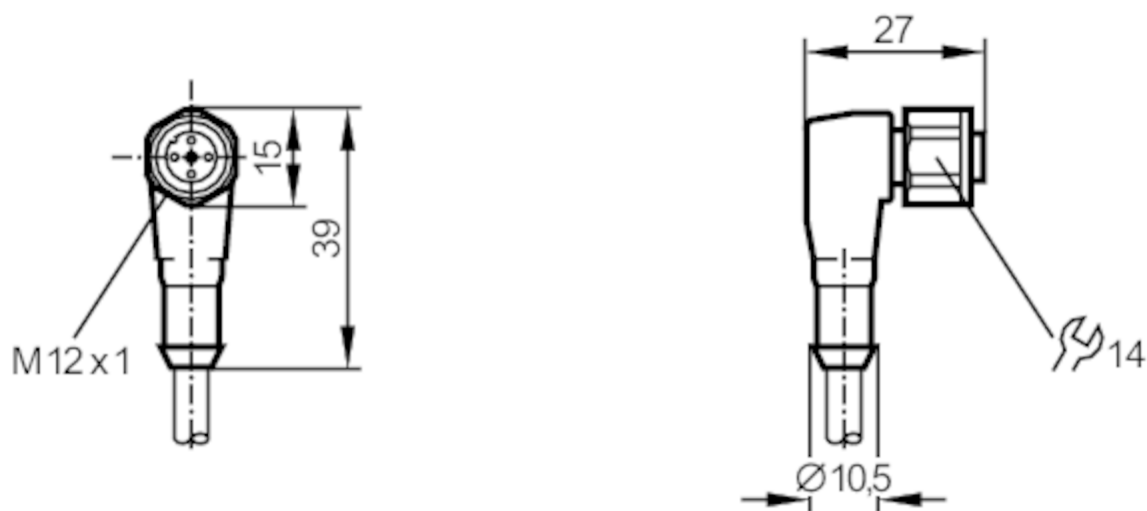

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 250 AC / < 300 DC

Operating conditions

Ambient temperature

[°C]

-25...70

Protection

IP 67

Mechanical data

Dimensions

[mm]

27 x 15 x 39

Materials

PVC

Moulded-body material

PVC

Material nut

stainless steel (316L/1.4404)

Remarks

Pack quantity

1 pcs.

E10745



Connecting cable with socket

 
ADOAH040VAS0020E04

Electrical connection


Cable: 20 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

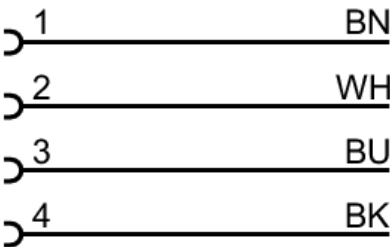

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white