


# E10924



## Connection cable

VDOGG030--S00,6H03STGF030MSS

Article no longer available - archive entry

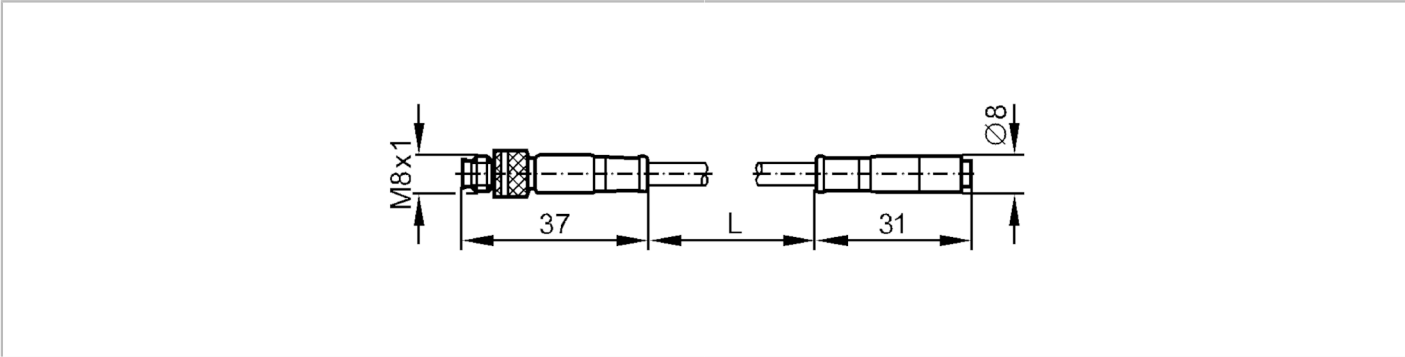

### Application

|                 |              |
|-----------------|--------------|
| Special feature | Halogen-free |
|-----------------|--------------|

### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...55 DC |
| Protection class  |     | III        |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 65    |

### Mechanical data


|                       |                      |
|-----------------------|----------------------|
| Materials             | TPU                  |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

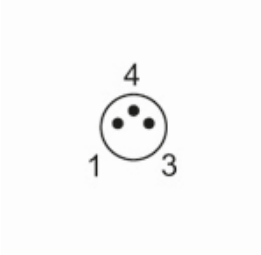

# E10924



## Connection cable

VDOGG030--S00,6H03STGF030MSS

### Electrical connection

Cable: 0.6 m, TPU, Halogen-free; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

