

E10251




Connecting cable with socket

ADOGH040ZDS0002A03

Article no longer available - archive entry

Alternative articles: EVC001
When selecting an alternative article and accessories please note that technical data may differ!

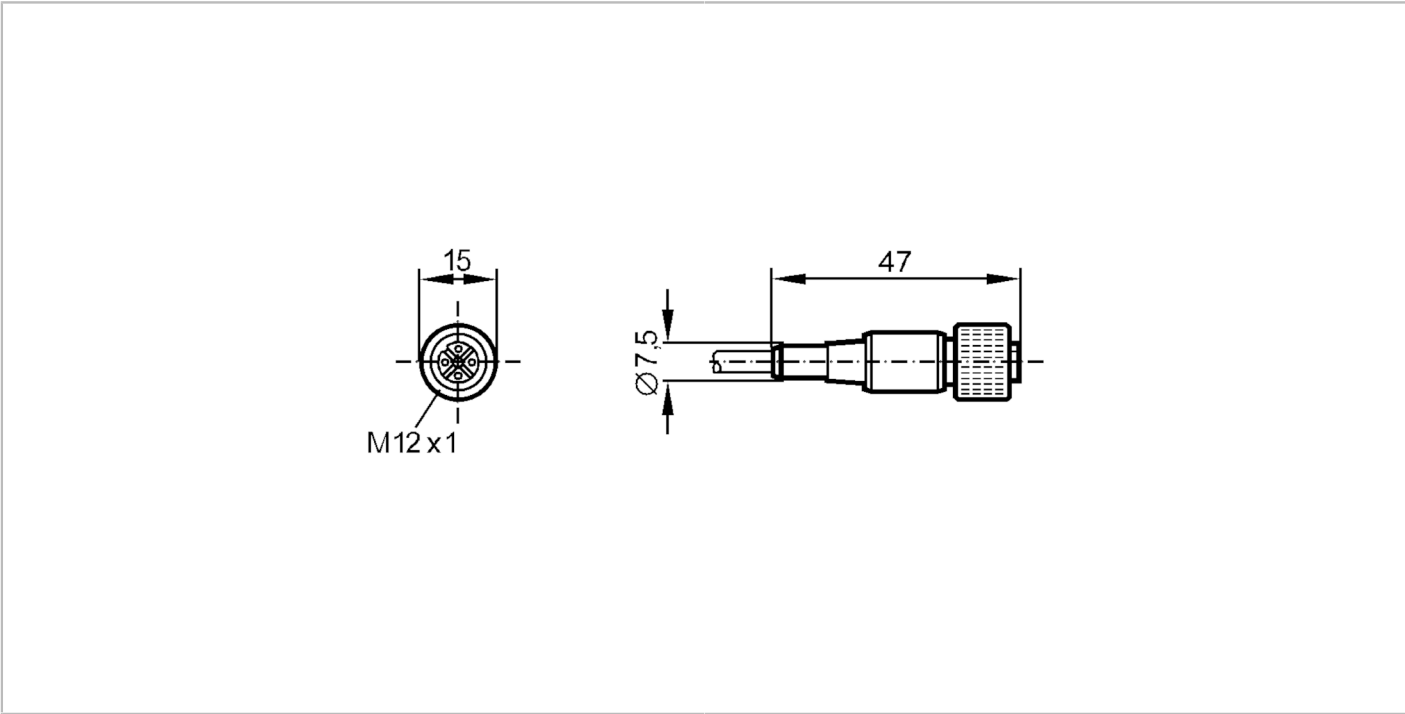

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	15 x 15 x 47
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10251



Connecting cable with socket

ADOGH040ZDS0002A03

Electrical connection


Cable: 2 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection

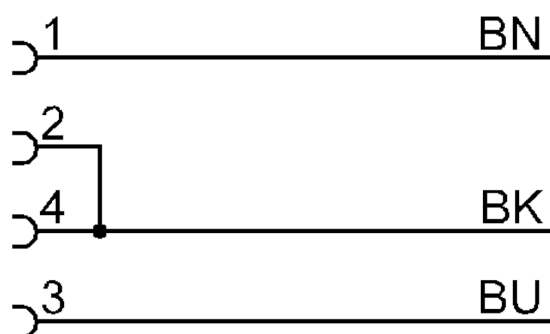

BN =
BK =
BU =

Core colours :
brown
black
blue