


## Connection cable

VDOAH043MSS0001H04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC037

When selecting an alternative article and accessories please note that technical data may differ!

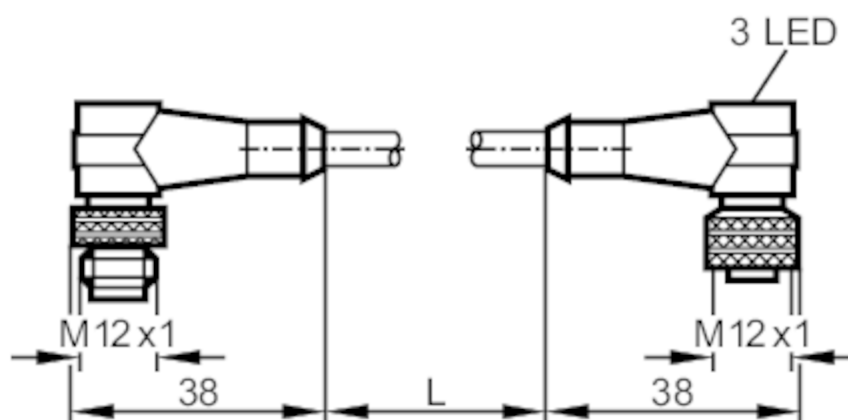

| Application                   |                                                        |                 |
|-------------------------------|--------------------------------------------------------|-----------------|
| Special feature               | Free from silicone; Halogen-free; Gold-plated contacts |                 |
| Free from silicone            | yes                                                    |                 |
| Electrical data               |                                                        |                 |
| Operating voltage             | [V]                                                    | 10...30 DC      |
| Max. current load total       | [A]                                                    | 3               |
| Outputs                       |                                                        |                 |
| Electrical design             | PNP                                                    |                 |
| Operating conditions          |                                                        |                 |
| Ambient temperature           | [°C]                                                   | -25...85        |
| Protection                    | IP 68                                                  |                 |
| Mechanical data               |                                                        |                 |
| Materials                     | PUR                                                    |                 |
| Moulded-body material         | PUR                                                    |                 |
| Material nut                  | brass, nickel-plated                                   |                 |
| Displays / operating elements |                                                        |                 |
| Display                       | switching status                                       | 2 x LED, yellow |
|                               | operation                                              | 1 x LED, green  |



## Connection cable

VDOAH043MSS0001H04STAH040MSS

### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

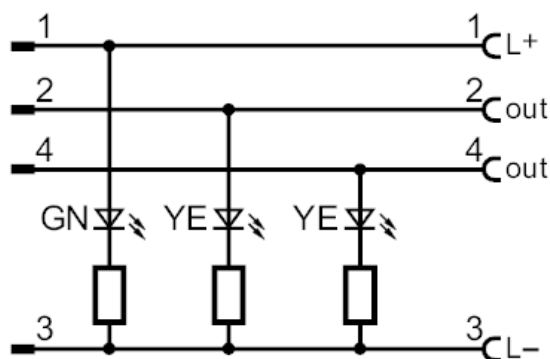

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

